




DIN 85 A

~ISO 1580

Norm zurückgezogen

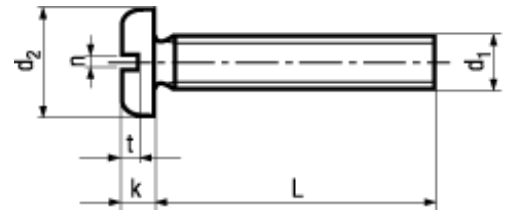

BN 536

Flachkopfschrauben Pan-Head

mit Schlitz

Messing

vernickelt

- ~UNI 6108
- ~ČSN 021137

M2,5: nach ISO 1580

Article#	d ₁	d ₂	k	n	t min.	L
1203002	M2,5	5	1,5	0,6	0,6	4
1203010						5
1203029						6
1203037						8
1203045						10
1203053						12
1203088						16
1203290	M3	6	1,8	0,8	0,7	4
1203304						5
1203312						6
1203320						8
1203339						10
1203347						12
1203363						16
1203398						20
1203479	(M3,5)	7	2,1	1	0,8	5
1203487						6
1203495						8
1203509						10
1203517						12
1203533						16
1203568						20
1203614	M4	8	2,4	1,2	1	4
1203622						5
1203630						6

Article#	d ₁	d ₂	k	n	t min.	L
1203649	M4	8	2,4	1,2	1	8
1203657						10
1203665						12
1203681						16
1203800	M5	10	3	1,2	1,2	6
1203819						8
1203827						10
1203835						12
1203851						16
1203886						20
1203908						25
1203916						30
1203967	M6	12	3,6	1,6	1,4	8
1203975						10
1203983						12
1204009						16
1204025						20