


Gegenmutter GM-INOX

Metr.

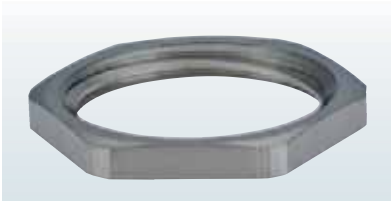


Material

INOX 1.4305



 
// weitere Größen auf Anfrage
// andere Edelstähle auf Anfrage



IG	H mm	 mm	Best.-Nr.
M 12 x 1,5	2,8	15	1.161.1200.58
M 16 x 1,5	2,8	19	1.161.1600.58
M 20 x 1,5	3	24	1.161.2000.58
M 25 x 1,5	3,5	30	1.161.2500.58
M 32 x 1,5	3,5	36	1.161.3200.58
M 40 x 1,5	5	46	1.161.4000.58
M 50 x 1,5	5	57	1.161.5000.58
M 63 x 1,5	6	70	1.161.6300.58

Gegenmutter GM-INOX

PG

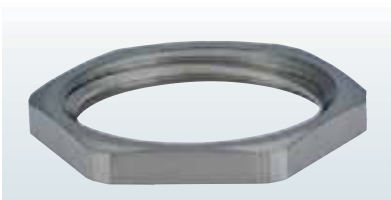


Material

INOX 1.4305



 // weitere Größen auf Anfrage
// andere Edelstähle auf Anfrage



IG	H mm	 mm	Best.-Nr.
PG 7	2,8	17	1.161.0700.08
PG 9	2,8	22	1.161.0900.08
PG 11	3	22	1.161.1100.08
PG 13,5	3	24	1.161.1300.08
PG 16	3	27	1.161.1600.08
PG 21	3,5	32	1.161.2100.08
PG 29	4	41	1.161.2900.08
PG 36	5	50	1.161.3600.08