

Electrical and Acoustical Parameter

Rated Voltage (VDC)	12.0
Operating Voltage (VDC)	5.0-28.0
Current Consumption (mA@rated voltage)	max. 20.0
Sound Pressure Level (dBA@1m, rated voltage)	85+/-3
Resonance Frequency (Hz)	2900±500
Tone	Continuous and Pulse Tone
Pulse Rate	80 ± 20c/m
	On/Off time 50% ± 20%
Remark:	n.a.

Mechanical, Environmental Parameter


Contact	Faston 6.3
Operating Temperature (°C)	-20 to +75
Storage Temperature (°C)	-30 to +80
Material Housing	ABS
Colour Housing	grey
IP Rating	65
Component weight (g)	40
Packaging	Box
Remark:	

Approval

RoHs	☒
UL	☐

Designed by	MZ	09.12.2015	Dimensions without tolerance ±0.5mm	Index: 00	Current date
Released by	CB	09.12.2015	Drawing number 151209.3BZ		09.12.2015
Changed by					Page 1 of 3

Drawing of Component

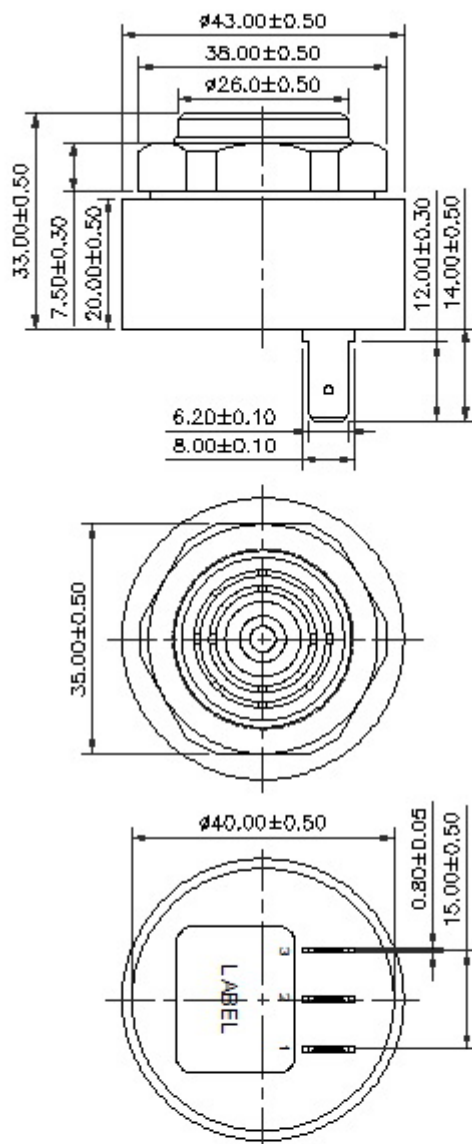

Label:



Designed by	MZ	09.12.2015	Dimensions without tolerance ±0.5mm	Index: 00	Current date
Released by	CB	09.12.2015	Drawing number	151209.3BZ	09.12.2015
Changed by					Page 2 of 3

Reliability Test

n.a.

Packaging Information

20pcs/carton

Revision Table

Index Nr.	Date Reason - Procedure Change description	Drawing Date	implementation	Comments
			LS-Nr.: Date	

Designed by	MZ	09.12.2015	Dimensions without tolerance $\pm 0.5\text{mm}$	Index: 00	Current date
Released by	CB	09.12.2015	Drawing number 151209.3BZ		09.12.2015
Changed by					Page 3 of 3