

NEO PC 322215 G

FIBOX
Enclosing innovations



Sample image

Order symbol: NEO PC 322215 G

EAN: 6418074311337

Product nbr: 4810000


El. number:

Description: Hinged polycarbonate enclosure with grey cover

- Finland: 3424407
- Denmark: 8212098022
- Sweden: 2506215

Remarks:

Including: Polycarbonate base and cover, mounting screws for mountingplate/DIN rail.

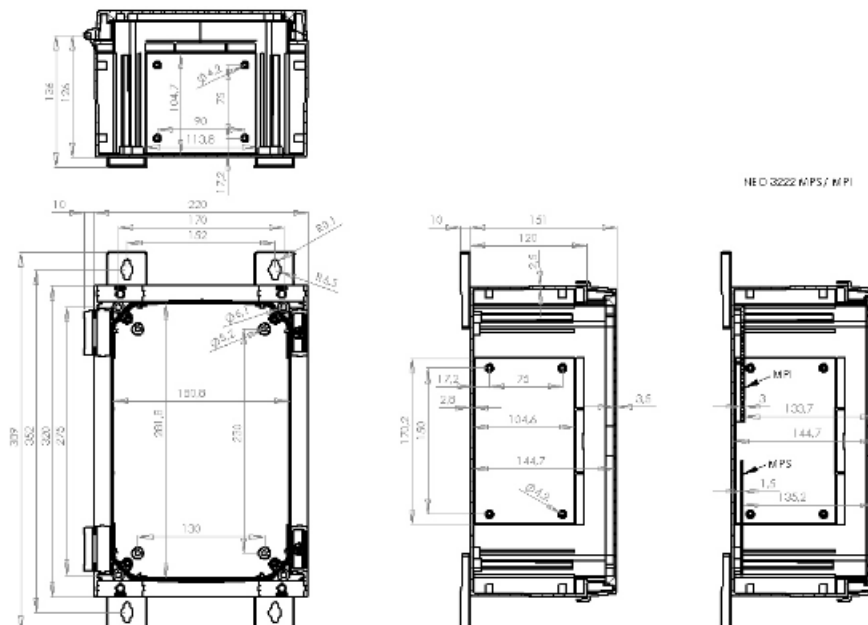

Dimensions:	Height	Width	Depth
mm:	320	220	150
inch:	12.6	8.66	5.91

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

NEO MPI 3222	Multiperforated plastic mounting plate (280 x 180 x 3)
NEO MPS 3222	Metal mounting plate (280 x 180 x 1)
PMK NEO 20	Pole mounting kit (300 x 200 x 30)
WMK NEO plastic	Wall mounting kit plastic (80 x 70 x 40)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK09;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate FI 40693 A1.pdf