

NEO PC 423215 T

FIBOX
Enclosing innovations



Sample image

Order symbol: NEO PC 423215 T

Product nbr: 4811002

Description: Hinged polycarbonate enclosure with transparent cover


Remarks:

Including: Polycarbonate base and cover, mounting screws for mountingplate/DIN rail.

EAN: 6418074311405

El. number:

- Finland: 3424416
- Denmark: 8212098077
- Sweden: 2506220

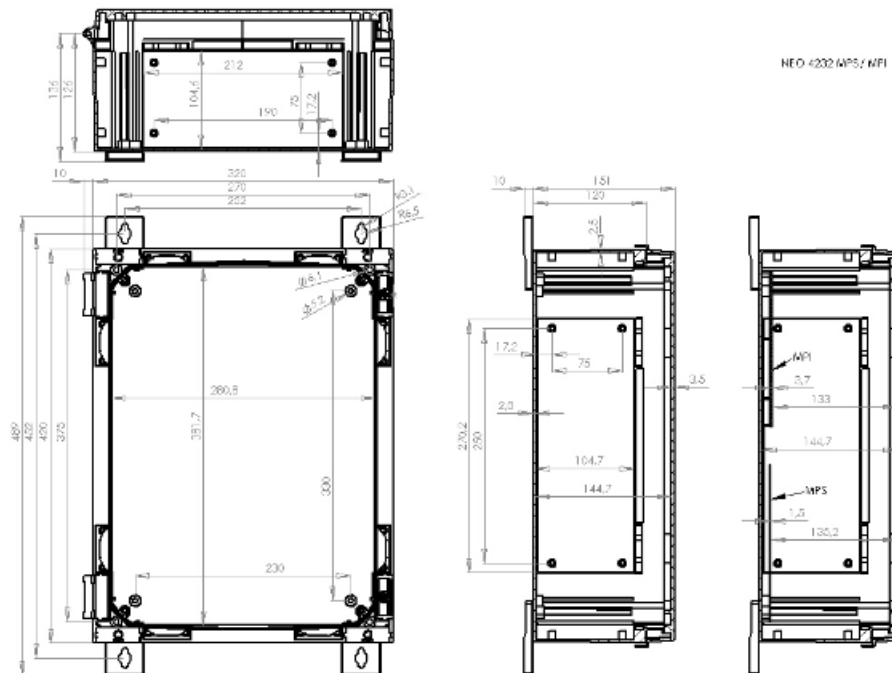

Dimensions:	Height	Width	Depth
mm:	420	320	150
inch:	16.54	12.6	5.91

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term):	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

NEO MPI 4232	Multiperforated plastic mounting plate (380 x 280 x 3)
NEO MPS 4232	Metal mounting plate (380 x 280 x 1)
PMK NEO 30	Pole mounting kit (400 x 300 x 30)
WMK NEO plastic	Wall mounting kit plastic (80 x 70 x 40)

Rating:

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK09;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate FI 40693 A1.pdf
