


Power cord (right angled C13), VDE approved, 6 ft

PC-186A-VDE

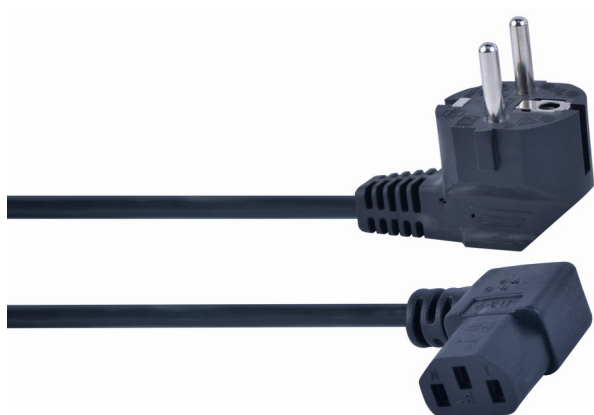

Features

- German Schuko input and right angled C13 output
- Molded plugs with integrated strain relief

Specifications

Total length: 6 ft (1.8 m)

Input plug: Shuko type with ground contact hole and 4.9 mm pins

Output plug: right angled C13

Packaging

Q'ty in crtn, pcs	100
Crtn volume, CUM	0.043
Crtn weight, kgs	20.5
Individual package size LxWxH:	190x115x35 mm
Carton size LxWxH:	315x400x340 mm
Country of origin	CN
Barcode	8716309047005
Customs code	8544429090

Certificates

