


Power cord C13), VDE approved, 10 m

PC-186-VDE-10M

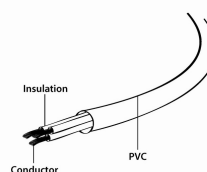

Features

- VDE approved power cord
- German Schuko input and C13 output
- Molded plugs with integrated strain relief

Specifications

Length: 10 m

Input plug: Shuko type with ground contact hole and 4.9 mm pins

Output plug: C13

Packaging

Q'ty in crtn, pcs
Crtn volume, CUM
Crtn weight, kgs
Individual package size LxWxH:
Carton size LxWxH:
Country of origin
Barcode
Customs code

25
0.047
22.02
300x160x70 mm
420x320x350 mm
CN
8716309026758
8544429090

Certificates

