


BATTERY CHARGER BC-20 PRO

20A (230V/12V) 7 - STAGE



Input voltage range:	190÷265VAC
Bulk/Absorption charging:	14.2 / 14.6 / 14.8 VDC
Floating charging:	13.2 / 13.5 / 13.8 VDC
Power supply mode:	13.2 / 13.4 / 13.8 VDC
Maximum power:	300W
Maximum charging current:	20A
Recommended battery capacity:	25-200Ah
Supply fuse:	3A
Charging fuse:	25A
Shortcut protection:	YES
Thermal protection:	80°C
Overvoltage protection:	YES
Reverse polarity protection:	YES
Operating temperature:	0°C ~ +40°C
Efficiency:	> 88%
Cooling:	Active (load dependent)
Supply socket:	Cable with 230VAC plug
Ground terminal:	YES
Case:	Aluminium
Protection:	IP21
Dimensions [mm]:	175x170x95
Weight [kg]:	1.27
Product code:	5903332566136

Charger set

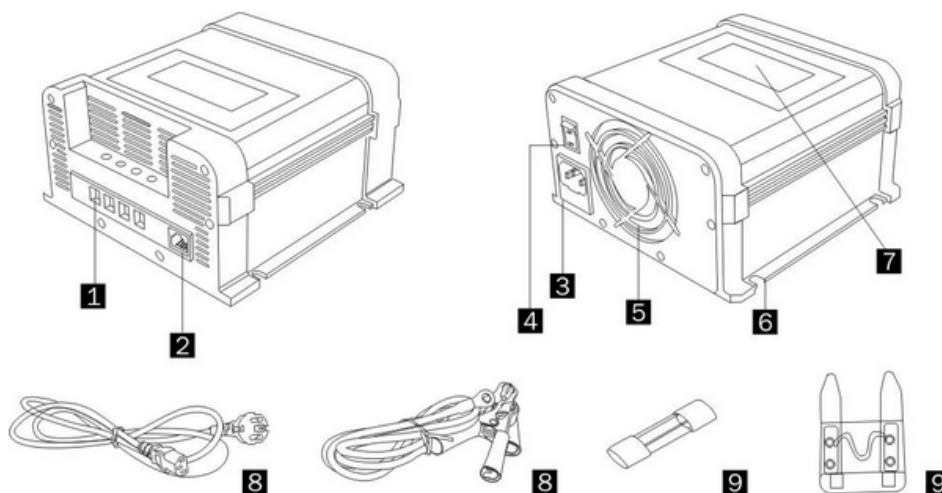

(1) Charging terminals, (2) Remote control terminal (optional), (3) Supply socket, (4) Main switch, (5) Fan, (6) Mounting holes, (7) LCD, (8) Cables, (9) Fuses

www.powerinverters.pl



PROGRAM REGIONALNY
 NARODOWA STRATEGIA SPÓJNOŚCI



Projekt współfinansowany przez Unię Europejską z Europejskiego Funduszu Rozwoju Regionalnego oraz z budżetu państwa.

