


Circlips for shafts bulk

BN 679

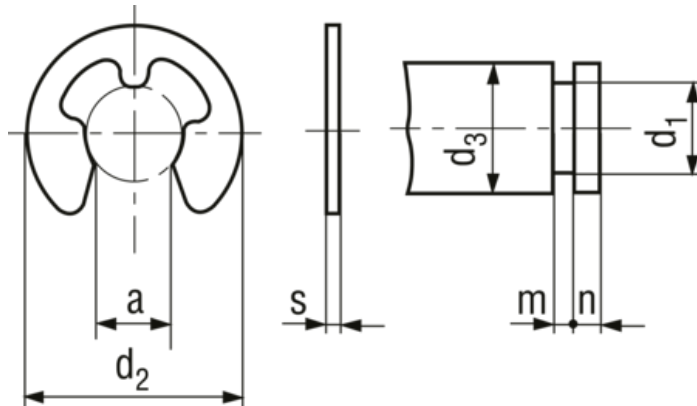

Product description

- 1.4116 / 1.4122 / 1.4034: at manufacturer's option

Material

Stainless steel

Material type

1.4116 / 1.4122 / 1.4034

Standard

DIN 6799, ~UNI 7434, ~ČSN 022929

Warnings

Fasteners out of martensitic stainless steel (e.g. 1.4116 / 1.4122 / 1.4034): susceptible to stress corrosion cracking under certain environmental conditions!

Article no	d1 h11	d2 max fitted	a ± IT 10 not fitted	s	Tolerance	d3 min	d3 max	m min	n min
1254464	1.2	3.25	1.01	0.3	0.02	1.4	2	0.34	0.6
1254472	1.5	4.25	1.28	0.4	0.02	2	2.5	0.44	0.8
1254480	1.9	4.8	1.61	0.5	0.02	2.5	3	0.54	1
1254499	2.3	6.3	1.94	0.6	0.02	3	4	0.64	1
1254502	3.2	7.3	2.7	0.6	0.02	4	5	0.64	1
1254510	4	9.3	3.34	0.7	0.02	5	7	0.74	1.2
1254529	5	11.3	4.11	0.7	0.02	6	8	0.74	1.2
1254537	6	12.3	5.26	0.7	0.02	7	9	0.74	1.2
1254545	7	14.3	5.84	0.9	0.02	8	11	0.94	1.5
1254553	8	16.3	6.52	1	0.03	9	12	1.05	1.8
1254561	9	18.8	7.63	1.1	0.03	10	14	1.15	2
1254588	10	20.4	8.32	1.2	0.03	11	15	1.25	2
1254596	12	23.4	10.45	1.3	0.03	13	18	1.35	2.5
1254618	15	29.4	12.61	1.5	0.03	16	24	1.55	3
1254626	19	37.6	15.92	1.75	0.03	20	31	1.8	3.5
1254634	24	44.6	21.88	2	0.03	25	38	2.05	4