


FTP Cat5e Patch cord, grey, 7.5 m

PP22-7.5M

- FTP Patch cord with moulded strain relief 50u" 8P8C plugs, 7.5 meters

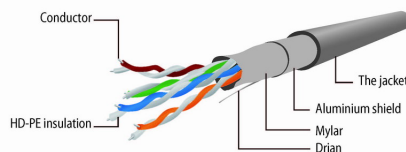

Features

- Foil shielded twisted pair patch cord

Specifications

Patch cord Enhanced category 5 FTP (shielded)
Length: according to the item
Structure: AWG 26 (7 x 0.15 mm wire), CCA
HDPE insulation of the wire: 0.85 mm
With LDPE filler: not used
With polyester tape
With aluminum foil
Drain hose: 7 x 0.12 mm CCA
PVC outer insulation: 5.0 mm
Color: according to the item
Operation up to 100 MHz

Packaging

Q'ty in crtn, pcs
Crtn volume, CUM
Crtn weight, kgs
Individual package size LxWxH:
Carton size LxWxH:
Country of origin
Barcode
Customs code

28
0.023
5.4
250x150x40 mm
385x295x200 mm
CN
8716309011655
8544421000

Certificates

