


UTP Cat6 Patch cord, grey, 20 m

PP6U-20M

- Perfect connection
- Gold plated contacts

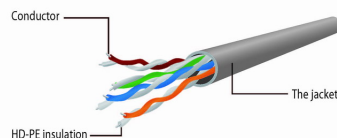

Features

- CAT6 stranded unshielded (UTP) patch cord, 8P8C
- Snagless boots

Specifications

Patch cord category 6 UTP (unshielded)
Length: according to the item
Structure: AWG 26 (7 x 0.15 mm wire), CCA
HDPE insulation of the wire: 0.85 mm
With LDPE filler
With polyester tape: not used
With aluminum foil: not used
Drain hose: not used
PVC outer insulation: 6.2 mm
Color: according to the item
Operation up to 250 MHz

Packaging

Q'ty in crtn, pcs	20
Crtn volume, CUM	0.048
Crtn weight, kgs	9.08
Individual package size LxWxH:	250x175x50 mm
Carton size LxWxH:	400x300x400 mm
Country of origin	CN
Barcode	8716309102018
Customs code	8544421000

Certificates

