


LOW VOLTAGE DC CABLE



Specification:

Model	DC.EXT.0200.0100
DC Socket	5,5x2,1mm [center positive]
DC Plug	5,5x2,1mm [center positive]
Recommended voltage	0 - 48V
Max Current	5A
Dielectric Strength	500 VDC
Operating temperature	-20°C to +70°C
Cord Length	1000mm
Cable Diameter	2x2mm
Wire Diameter	2x0,5mm ²
ROHS	+

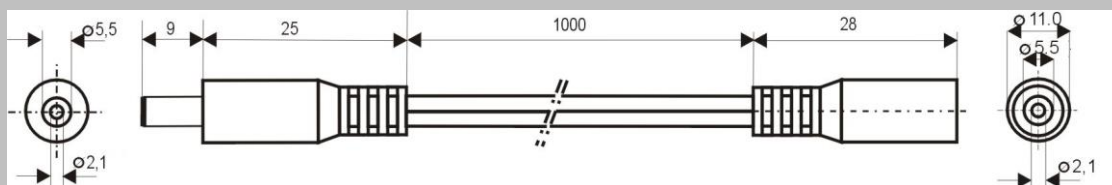

Made in Poland