

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0039013109

Status:


Active

Overview:

Mini-Fit Family Power Connectors

Description:

Mini-Fit Jr. Plug Housing, Dual Row, 10 Circuits, UL 94V-0, without Panel Mounting Ears, Natural

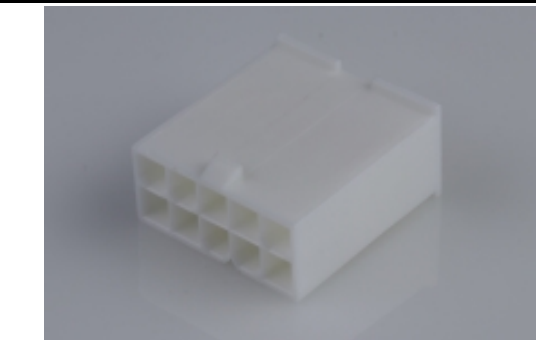

Series image - Reference only

Documents:

- 3D Model (PDF)

3D Model

Drawing (PDF)

Product Specification PS-45750-001-001 (PDF)

Product Specification PS-5556-001-001 (PDF)

Application Specification 55560001-AS-000 (PDF)
- Application Specification AS-5557-001-001 (PDF)

Packaging Specification PK-5559-002-001 (PDF)

Test Summary 55560010-TS-000 (PDF)

Test Summary TS-5556-002-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA

UL

LR19980

E29179

General

Product Family

Series

Application

Comments

Crimp Housings

5559

Power, Wire-to-Board, Wire-to-Wire

Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information.

Overview

Product Name

UPC

Mini-Fit Family Power Connectors

Mini-Fit Jr.

800754204040

Physical

Breakaway

Circuits (maximum)

Color - Resin

Flammability

Gender

Glow-Wire Capable

Keying to Mating Part

Lock to Mating Part

Material - Resin

Net Weight

Number of Rows

Packaging Type

Panel Mount

Pitch - Mating Interface

Pitch - Termination Interface

Polarized to Mating Part

Stackable

Temperature Range - Operating

No

10

Natural

94V-0

Plug

No

None

Yes

Nylon

3.000/g

2

Bag

No

4.20mm

4.20mm

Yes

No

-40° to +105°C

Electrical

Current - Maximum per Contact

13.0A

Material Info

Engineering Number

5559-10P1-210

Reference - Drawing Numbers

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -  
D(2021)10043-DC (17  
Jan 2022)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

5559 Series

Mates With

Mini-Fit Jr. Receptacle Housing [39012105](#)  
<br>Mini-Fit Jr. Cable Assembly [245135](#)

Use With

Mini-Fit Male Crimp Terminals [5558](#)  
<br>Mini-Fit Plus HCS Crimp Terminals  
[46012](#) <br>Mini-Fit Jr. Grounding Pin [30490](#)  
<br>Mini-Fit Pre-Crimped Leads [797580005](#)  
, [797580013](#) <br>Mini-Fit Jr. Backshell  
[204723](#)

|                           |                                   |
|---------------------------|-----------------------------------|
| Application Specification | 55560001-AS-000, AS-5557-001-001  |
| Packaging Specification   | PK-5559-002-001                   |
| Product Specification     | PS-45750-001-001, PS-5556-001-001 |
| Sales Drawing             | 55590001-SD-000                   |
| Test Summary              | 55560010-TS-000, TS-5556-002-001  |

This document was generated on 03/03/2022

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**