



UK power cord (C5), 13 A, 6 ft PC-187-ML12

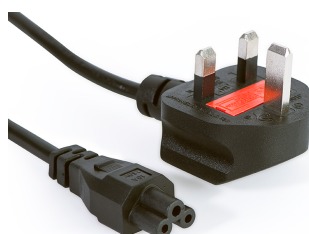

Features

- UK 13 A power cord
- UK 3-pin plug input to C13 output
- BS-approved
- Molded plugs with integrated strain relief

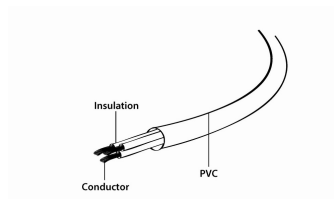

Specifications

Length: 6 ft (1.8 m)
Input plug: UK plug (BS 1363)
Output plug: C5

Packaging

Q'ty in crtn, pcs	100
Crtn volume, CUM	0.053
Crtn weight, kgs	22.6
Individual package size LxWxH:	60x200x115 mm
Carton size LxWxH:	420x410x310 mm
Country of origin	CN
Barcode	8716309023399
Customs code	8544429090

Certificates

