

ARCA 404021 No MP



Sample image

Order symbol: ARCA 404021 No MP

Product nbr: 8120009N

Description: Cabinet. PC


Remarks: Grey cover. 2-point locking.

EAN: 6418074086679

El. number:

- Finland:
- Denmark:
- Sweden: 2506468

Including: Cabinet base. door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

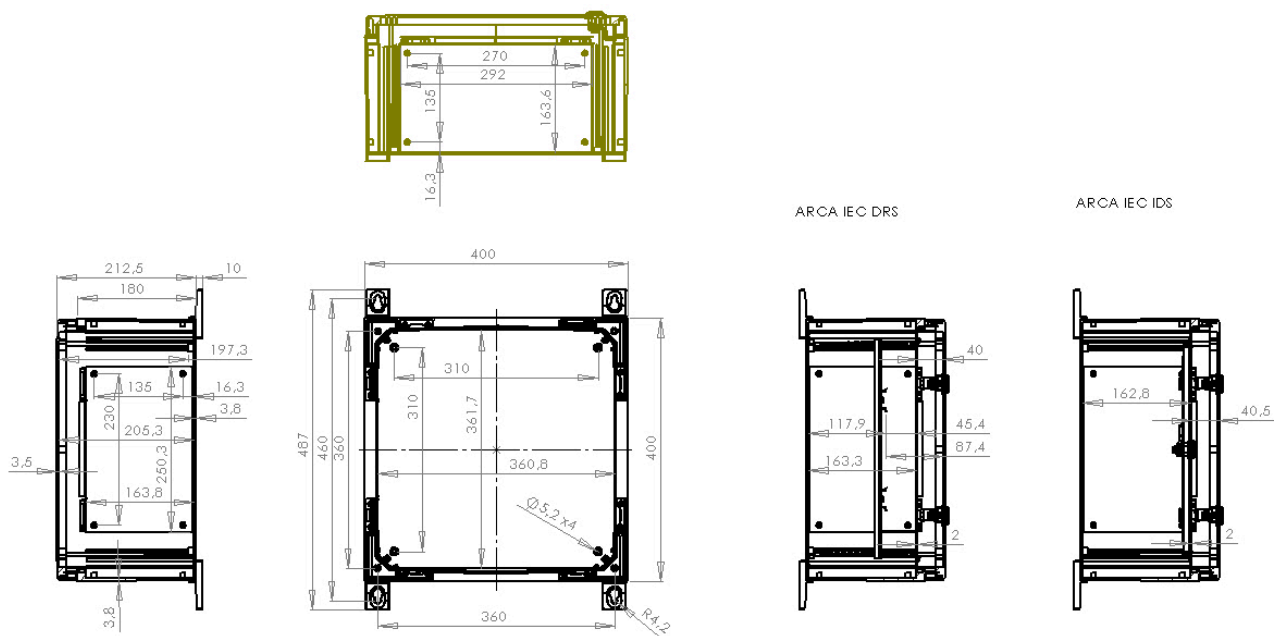

Dimensions:	Height	Width	Depth
mm:	400	400	210
inch:	15.75	15.75	8.58

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

IDS ARCA 4040	Inner door set (380 x 380 x 30)
MPX ARCA 4040	Mounting plate (350x350 mm) (350 x 350 x 5)
MPMP ARCA 4040	Mounting plate multiperforated (350x350x2 mm - ø3.6 mm) (350 x 350 x 2)
DRS ARCA 404021	DIN rail frame set (385 x 385 x35)
MPS ARCA 4040	Mounting plate (350x350x2 mm) (350 x 350 x 2)
MPP ARCA 4040	Mounting plate perforated (350x350x2 mm - 26x11 mm) (350 x 350 x 2)

Rating:

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA

Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

Certificates:

Certificate FI 40467