

ARCA 505021

FIBOX
Enclosing innovations



Sample image

Order symbol: ARCA 505021

Product nbr: 8120032

Description: Cabinet. PC


Remarks: Grey cover. 2-point locking.

EAN: 6418074314642

El. number:





- Finland:
- Denmark:
- Sweden: 2506459

Including: Cabinet base. door with PUR gasket. mounting plate. screws for mounting plate. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

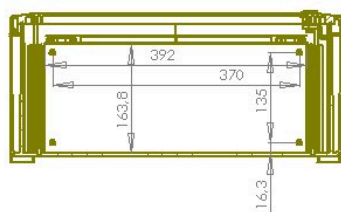

ARCA IEC DRS

ARCA IEC IDS

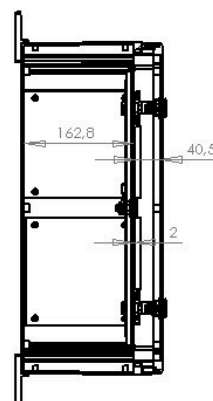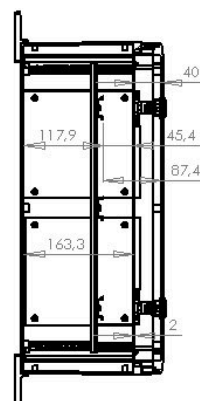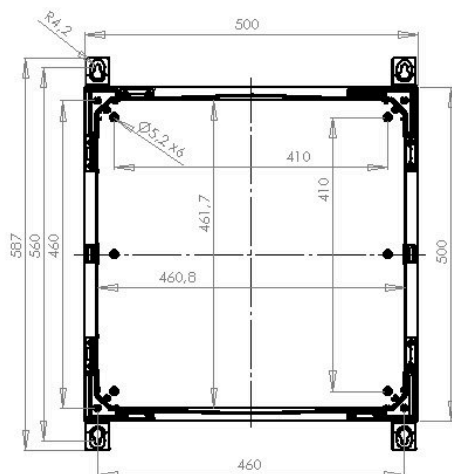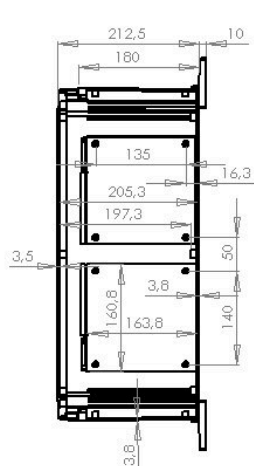

Dimensions:

Height	Width	Depth
mm:	500	500
inch:	19.69	19.69

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	RAL 7035 -light grey
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Accessories:

MPMP ARCA 5050	Mounting plate multiperforated (450x450x2 mm - ø3.6 mm) (450 x 450 x 2)
MPX ARCA 5050	Mounting plate (450x450 mm) (450 x 450 x 5)
MPS ARCA 5050	Mounting plate (450x450x2 mm) (450 x 450 x 2)
DRS ARCA 505021	DIN rail frame set (485 x 485 x35)
RCS ARCA 5050	Rain canopy set for size 5050 (20 x 500 x 30)
IDS ARCA 5050	Inner door set (480 x 480 x 30)
MPP ARCA 5050	Mounting plate perforated (450x450x2 mm - 26x11 mm) (450 x 450 x 2)

Rating:

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK10;
Electrical insulation:	Totally insulated

Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	NEMA 1, 4, 4X, 12 and 13

Certificates:

Certificate FI 40467