

CAB PC 203018 T3B

FIBOX
Enclosing innovations



Sample image

Order symbol: CAB PC 203018 T3B

EAN: 6418074012548

Product nbr: 8113036



El. number:

Description: Smoked transparent door

- Finland:
- Denmark: 8212019810
- Sweden:

Remarks: Lock on the short side

Including: Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key, screws for mounting plate/DIN-rail and corner plugs.

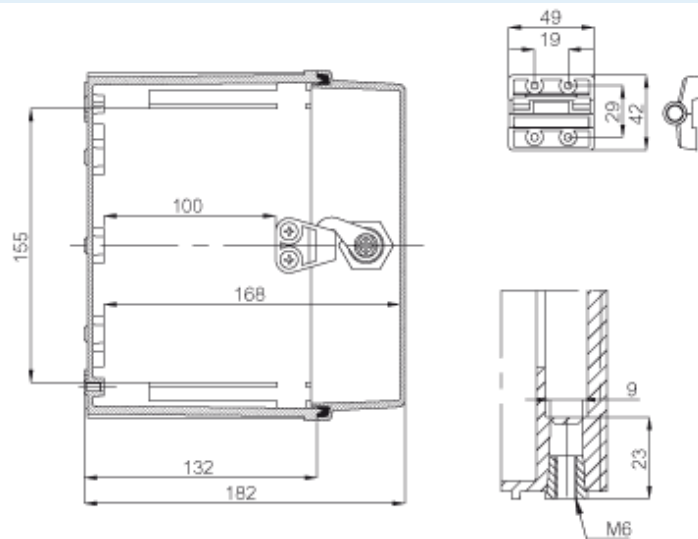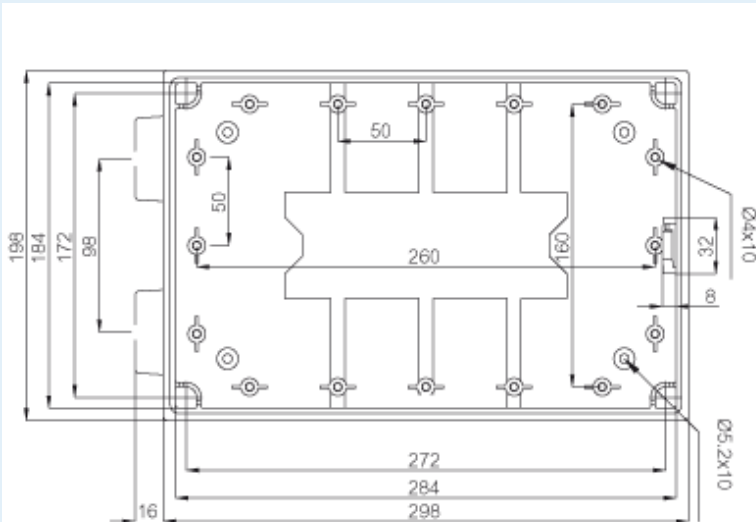

Dimensions:

	Height	Width	Depth
mm:	200	300	180
inch:	7.87	11.81	7.09

Materials:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey

Accessories:

MB 12225	Swing door kit
AL	
EKIV 27	DIN-35 Mounting rail, for enclosures: (266 x 35 x 1)
DRF 23	DIN rail frame kit, for enclosures:
FP A 23	Swing-out door/Front panel (aluminum), for enclosures: (168 x 268 x 1)
EKIV 17	DIN-35 Mounting rail, for enclosures:

Cover colour:	Clear transparent
Gasket material:	Polyurethane

	(166 x 35 x 1)
EKIV 23	Back Panel. for enclosures: (170 x 270 x 1)

Temperatures:	
Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

Rating:	
Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:	
Certificate FI 40854	