

CAB PC 304018 T3B

FIBOX
Enclosing innovations



Sample image

Order symbol: CAB PC 304018 T3B

Product nbr: 8113054

Description: Smoked transparent door


Remarks: Locks on the short side

Including: Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key, screws for mounting plate/DIN-rail and corner plugs.

EAN: 6418074012555

El. number:

- Finland:
- Denmark:
- Sweden:

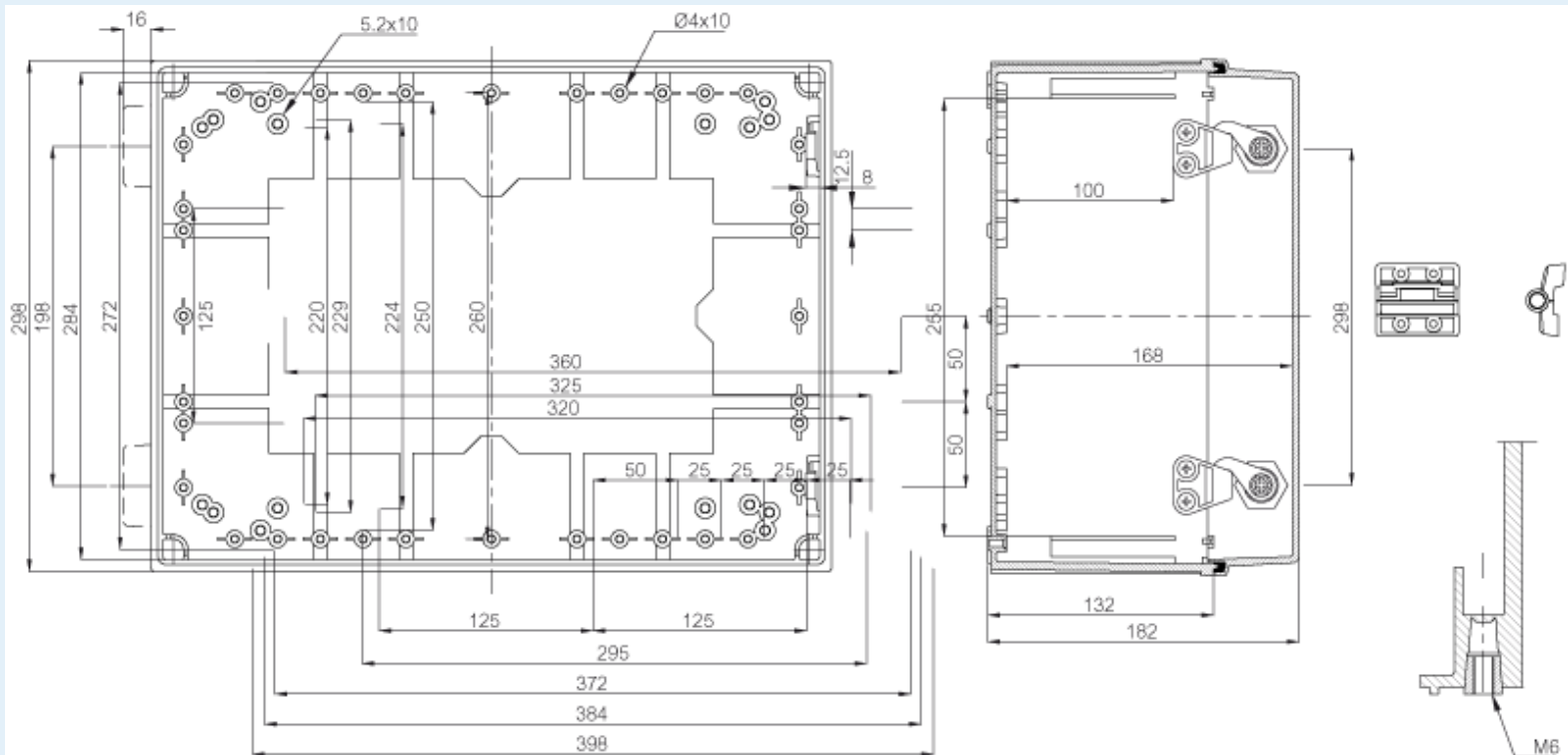

Dimensions:	Height	Width	Depth
mm:	300	400	180
inch:	11.81	15.75	7.09

Materials:

Accessories:

DRF 43/44 DIN rail frame kit, for enclosures:

MB 12225 Swing door kit

EKIV 37 DIN-35 Mounting rail, for enclosures: (366 x 35 x 1)

EKIV 27 DIN-35 Mounting rail, for enclosures:

Material:	Polycarbonate
Base colour:	RAL 7035 -light grey
Cover colour:	Clear transparent
Gasket material:	Polyurethane

Temperatures:

Temperature °C (short term)::	-40 ... 120
Temperature °C (continuous):	-40 ... 80
Temperature °F (short term):	-40 ... 250
Temperature °F (continuous):	-40 ... 175

	(266 x 35 x 1)
EKIV 43 PL	Back Panel. plastic. for enclosures: (370 x 270 x 2)
EKIV 43	Back Panel. for enclosures: (370 x 270 x 1)
FP A 43	Swing-out door/Front panel (aluminum). for enclosures: (268 x 368 x 1)

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"
Glow Wire Test (IEC 695-2-1) °C:	960 °C
NEMA Class	

Certificates:

Certificate FI 40854