


MPMP ARCA 5050

FIBOX
Enclosing innovations

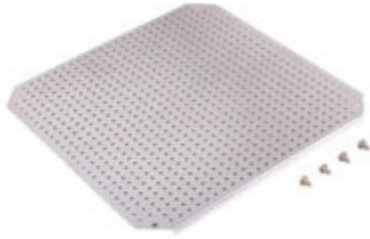

Sample image

Order symbol: MPMP ARCA 5050

Product nbr: 8120929

Description: Mounting plate
multi-perforated (450x450x2 mm -
ø3.6 mm)

Remarks: Galvanized steel. for size
500x500x210

Including:

EAN: 6418074314734

El. number:

- Finland:
- Denmark:
- Sweden:

Dimensions:	Length	Width	Height
-------------	--------	-------	--------

mm:		450	450
-----	--	-----	-----

inch:			
-------	--	--	--

Materials:

Material:

Base colour:

Cover colour:

Gasket material:

Temperatures:

Temperature °C (short term):

Temperature °C (continuous):

Temperature °F (short term):

Temperature °F (continuous):

Rating:

Ingress protection (EN 60529):	
--------------------------------	--

Impact Resistance (EN 62262):	
-------------------------------	--

Electrical insulation:	Not insulated
------------------------	---------------

Halogen free (DIN/VDE 0472, Part 815):	0
--	---

UV resistance:	-
----------------	---

Flammability Rating:	
----------------------	--

Glow Wire Test (IEC 695-2-1) °C:	
----------------------------------	--

NEMA Class	
------------	--

Certificates:
