

1256/C36-2

Bi-material microscrewdriver with 36 interchangeable 4-mm bits and magnetic extension



200 g

130x60x35 mm - 200 g

For precision jobs.

In compact anodized aluminium case.

art.	
012560100	1256/C36-2
	TX ⌘ T3-T4-T5-T6-T7-T8-T9-T10-T15 RTX ⊕ T6-T7-T8-T9-T10 PE ○ 0.7-0.9-1.3-1.5-2.0-2.5 mm LP ● 0.8-1.2-1.5-1.8-2.0-2.5-3.0-3.5-4.0 mm PH ⊕ PH000-PH00-PH0-PH1 PZ ⊕ PZ000-PZ00-PZ0-PZ1

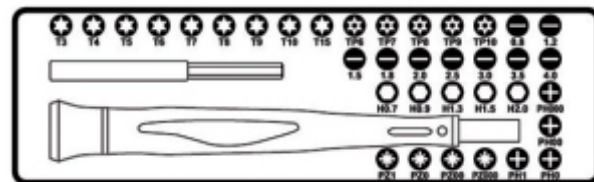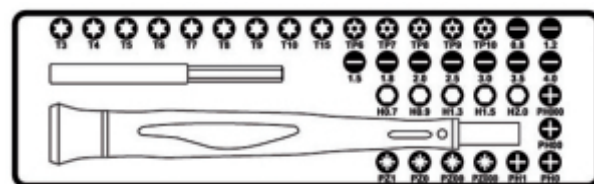

- n. 1256TX: ⌘ T3 - T4 - T5 - T6 - T7 T8 - T9 - T10 - T15
- n. 1256RTX: ⊕ T6 - T7 - T8 - T9 - T10
- n. 1256LP: ● 0,8 - 1,2 - 1,5 - 1,8 - 2 - 2,5 3 - 3,5 - 4 mm
- n. 1256PE: ○ 0,7 - 0,9 - 1,3 - 1,5 - 2 mm
- n. 1256PH: ⊕ PH000 - PH00 - PH0 - PH1
- n. 1256PZ: ⊕ PZ000 - PZ00 - PZ0 - PZ1
- n. 1256/20:
- n. 1256/30: