

DIN rail perforated - NS 35/ 7,5 PERF/...



1208131

<https://www.phoenixcontact.com/pc/products/1208131>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.



DIN rail perforated, acc. to EN 60715, material: Steel, galvanized, passivated with a thick layer, Standard profile, color: silver, as per customer specification: max. length: 2 m

DIN rail perforated - NS 35/ 7,5 PERF/...



1208131

<https://www.phoenixcontact.com/pc/products/1208131>

Commercial Data

Item number	1208131
Packing unit	1 pc
Minimum order quantity	20 pc
Note	Made to Order (non-returnable)
Product Key	BE7244
Catalog Page	Page 527 (C-3-2019)
Weight per Piece (including packing)	22.22 g
Weight per Piece (excluding packing)	22.22 g
Customs tariff number	72166190
Country of origin	DE

DIN rail perforated - NS 35/ 7,5 PERF/...



1208131


<https://www.phoenixcontact.com/pc/products/1208131>

Technical Data

Product properties

Product type	DIN rail
--------------	----------

Dimensions

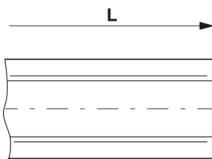Dimensional drawing	
Width	35 mm
Hole width	15 mm
Height	7.5 mm
Hole height	6.2 mm
Drill hole spacing	25 mm

Material specifications

Color	silver
Material	Steel
Coating	galvanized, passivated with a thick layer

Standards and regulations

Connection in acc. with standard	IEC / EN
Tests	acc. to EN 60715

DIN rail perforated - NS 35/ 7,5 PERF/...


1208131

<https://www.phoenixcontact.com/pc/products/1208131>



Drawings

Dimensional drawing

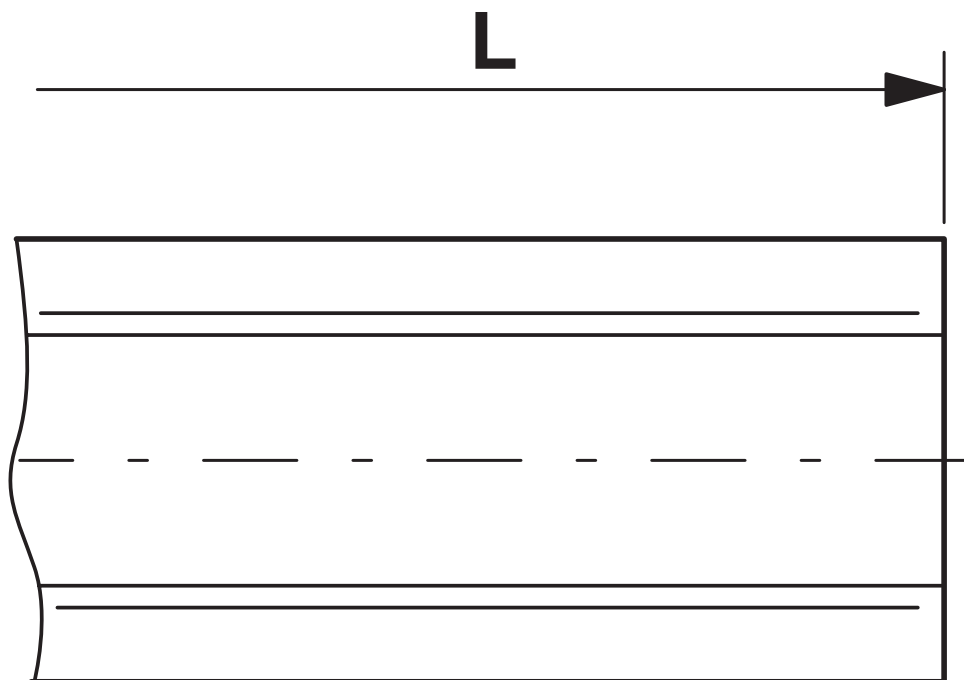

Phoenix Contact 2022 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT GmbH & Co. KG
Flachmarktstraße 8
D-32825 Blomberg
+49 (0) 5235-3 00
info@phoenixcontact.com