

CAB PC 405020 G3B

FIBOX
Enclosing innovations



Sample image

Order symbol: CAB PC 405020 G3B

EAN: 6418074012746

Product nbr: 8113364

El. number:



Description: Opaque door

- Finland:
- Denmark: 8212019849
- Sweden:


Remarks: Locks on the short side

Including: Cabinet base, door with PUR gasket, 3mm double bit lock(s) with key, screws for mounting plate/DIN-rail and corner plugs.


CAB 500x400x200

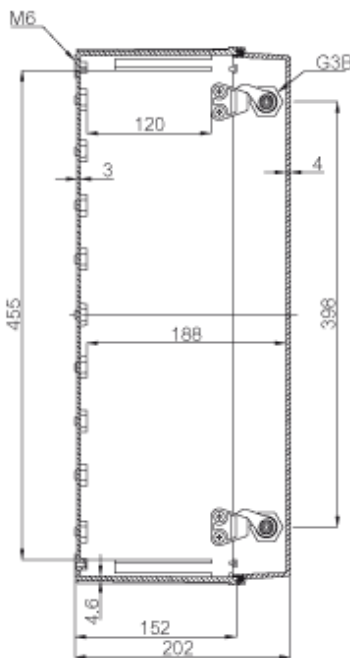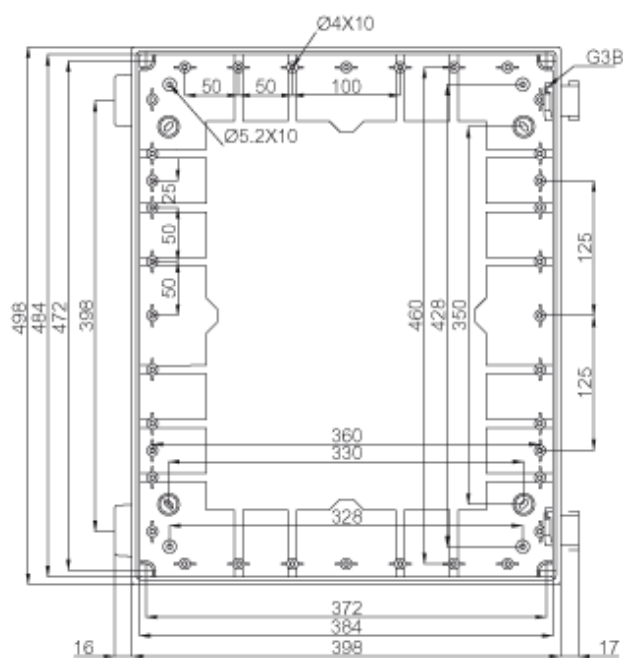


CAB 4050

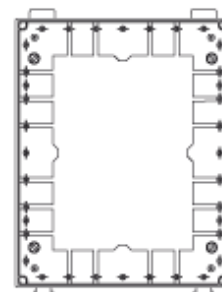

CAB 5040

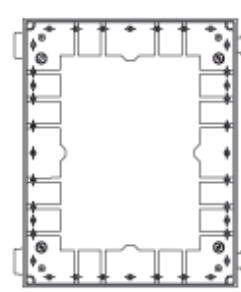

CAB 5040 G3B

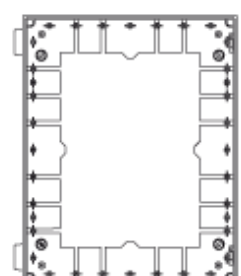

Dimensions:

	Height	Width	Depth
mm:	400	500	200
inch:	15.75	19.69	7.87

Materials:

Material:	Polycarbonate
-----------	---------------

Rating:

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK08;
Electrical insulation:	Totally insulated
Halogen free (DIN/VDE 0472, Part 815):	1
UV resistance:	UL 508
Flammability Rating:	UL 746C 5"

Base colour: RAL 7035 -light grey
Cover colour: RAL 7035 -light grey
Gasket material: Polyurethane

Glow Wire Test (IEC 695-2-1) °C: 960 °C
NEMA Class

Temperatures:

Temperature °C (short term):: -40 ... 120
Temperature °C (continuous): -40 ... 80
Temperature °F (short term): -40 ... 250
Temperature °F (continuous): -40 ... 175

Certificates:

Certificate FI 40854