


Screw plug, plastic

GSP M/MS

Metric thread

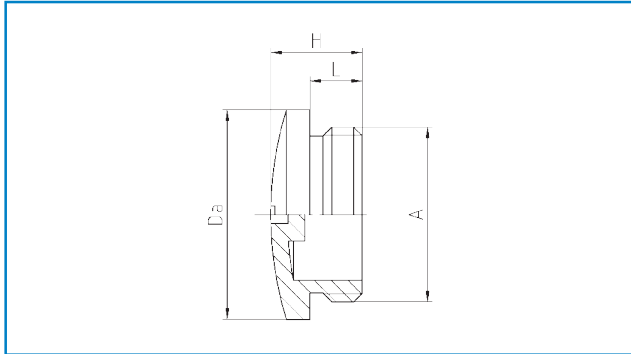

Technical details

Screw plug
Connecting thread

Polyamide PA6 GF30
metric as per EN 60423

Properties

- For secure sealing of unused threaded or clearance hole

Temperature range -30...+100 °C
Protection grade IP54/IP65 *
Higher protection grade IP65,
if assembled with sealing ring

Order symbol	Code	EAN	A	L mm	H mm	Da mm	Pack
RAL 7035: Screw plug, round							
GSP M12 slot	7016525	6418074056252	M12 x 1,5	6	10	15	100
GSP M16 slot	7016526	6418074056269	M16 x 1,5	6	10,5	20	100
GSP M20 slot	7016527	6418074056276	M20 x 1,5	6	10,5	24	100
GSP M25 slot	7016528	6418074056283	M25 x 1,5	8	13	30	100
GSP M32 slot	7016529	6418074056290	M32 x 1,5	8	13,5	37	100
GSP M40 slot	7016530	6418074056306	M40 x 1,5	8	14	46	50
GSP M50 slot	7016531	6418074056313	M50 x 1,5	10	16,5	56	50
GSP M63 slot	7016532	6418074056320	M63 x 1,5	12	17	70	50
RAL 7035: Screw plug, round, O-ring*							
GSP M12S slot	7016680	6418074091673	M12 x 1,5	6	10	15	100
GSP M16S slot	7016681	6418074091680	M16 x 1,5	6	10,5	20	100
GSP M20S slot	7016682	6418074091697	M20 x 1,5	6	10,5	24	100
GSP M25S slot	7016683	6418074091703	M25 x 1,5	8	13	30	100
GSP M32S slot	7016684	6418074091710	M32 x 1,5	8	13,5	37	100
GSP M40S slot	7016685	6418074091727	M40 x 1,5	8	14	46	50
GSP M50S slot	7016686	6418074091734	M50 x 1,5	10	16,5	56	50
GSP M63S slot	7016687	6418074091741	M63 x 1,5	12	17	70	50