


5988 VHB-MQ
Assortment of 66 tools for electrotechnical maintenance, EVA foam trays

Electrotechnical maintenance

		art.
	059880300	5988 VHB-MQ
	059880400	5988 VHB-MQ

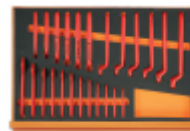


M49




M108



M161

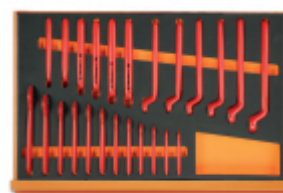

M49

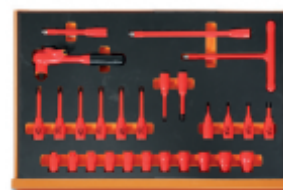

M108



M161

- n. 12 **52MQ**: single open end wrenches, 1000V 7-8-10-11-12-13-14-15-16-17-19-22 mm
- n. 12 **89MQ**: single ring wrenches 7-8-10-11-12-13-14-15-16-17-19-22 mm
- n. 4 **910MQ/PE**: socket drivers for hexagon screws $\odot$ 4-5-6-8 mm
- n. 11 **910MQ/B**: bi-hex sockets $\odot$ 7-8-10-11-12-13-14-15-16-17-19 mm
- n. 6 **910MQ/TX**: socket drivers for Torx® head screws $\odot$ T15-T20-T25-T27-T30-T40
- n. 2 **910MQ/XZN**: socket drivers with XZN® profile $\odot$ 8-10 mm
- n. 1 **910MQ/21**: 3/8" drive extension 125 mm
- n. 1 **910MQ/22**: 3/8" drive extension 250 mm
- n. 1 **910MQ/T**: 3/8" drive, T-handle
- n. 1 **910MQ/55**: 3/8" drive reversible ratchet
- n. 1 **1128MQ**: electrician's scissors
- n. 1 **1048MQ**: slip joint pliers, boxed joint 250 mm
- n. 1 **1082MQ**: diagonal cutting nippers 1000V $\square$ 160 mm
- n. 1 **1150MQ**: combination pliers 1000V $\equiv$ 180 mm
- n. 1 **1162MQ**: extra long flat nose pliers $\equiv$ 160 mm
- n. 1 **1164MQ**: extra-long bent flat nose pliers $\equiv$ 160 mm
- n. 4 **1272MQ**: screwdrivers for cross head Phillips® screws, 1000V $\oplus$ PH0x60 - PH1x80 - PH2x100 - PH3x150 mm
- n. 4 **1274MQ**: screwdrivers for headless slotted screws, 1000V $\bullet$ 2,5x75 - 3x100 - 4x100 - 5,5x125 mm
- n. 1 **1777MQ/U**: cable stripping knife, insulated