



HDMI 2.1 Cable

HDMI 2.1 Cable

More Details More Wonders



HDMI 2.1	8K	144HZ	21: 9
3D VISION	DYNAMIC HDR	12BIT	EARC
HIFI	VRR	48GBPS	QFT

Upgraded HDMI 2.1

Extreme Performance

Version	2.1	2.0
Picture quality	3D vision 7680*4320 pixels 1080P@160Hz, 2K@144Hz 4K@120Hz, 8K@60Hz Static HDR Dynamic HDR Variable Refresh Rate (VRR) Quick Media Switching (QMS) Automatic Low Latency Mode (ALLM)	3D vision 3840*2160 pixels 4K@60Hz Static HDR — — — —
Sound quality	Multiple audio streams 32 audio channels Auto-synchronization of audio and video 1536KHz audio sampling rate Enhanced Audio Return Channel (eARC)	Multiple audio streams 32 audio channels Auto-synchronization of audio and video 1536KHz audio sampling rate —
Rate	48Gbps max bandwidth Quick Frame Transfer (QFT)	18Gbps max bandwidth —

8K Resolution Ultra-HD Cinema Experience

144Hz refresh rate
21:9 wide-angle incredible view



3D Vision Cool. And Immersive

Be careful. Don't get lost in what looks so real



Panoramic sound

eARC

Once again promoted. Just Enjoy it

HDMI 2.1 features in enhanced audio return channel (eARC)



HiFi Audiophile-level sound

Get surrounded in the amazing sound



VRR Supported To Wipe out Lag and Crack

HDMI 2.1 supports variable refresh rate to realize synchronic
adjustment of frame rate for display and GPU
Now, get more scores in the smoother gaming



48Gbps Bandwidth & QFT

Faster transmission and no more delay
in the display



HDMI 1.4
10.2Gbps

HDMI 2.0
18Gbps

HDMI 2.1
48Gbps

Wide Applications



Smart box to TV



PC to projector

Multiple Modes

01

Dual screen
copy mode



02

Dual screen
expansion mode



03

Multi-screen
splicing



Compatible with Multiple Devices

Compatible with version 2.1
backward compatible
with version 2.0/1.4/1.3/1.2/1.1



Output Devices



Computer



Smart box



PS3/4

...

Display devices



TV



Monitor




Projector

...

Product Parameters

Brand	Vention
Name	HDMI 2.1 HD Cable
Model	AAN
Color	Black
Connector	HDMI Standard
Version	HDMI 2.1
Interface	Gold-plated
Resolution	1080P@160Hz/2K@144Hz/4K@120Hz/8K@60Hz
Conductor	Pure Copper
Shell	PVC
Shielding	Aluminum Foil + Metal Woven Mesh
Jacket	PVC
AWG	28AWG
OD	7.3mm
Length	1-3m
Warranty	1 Year
Packing	PE Bag

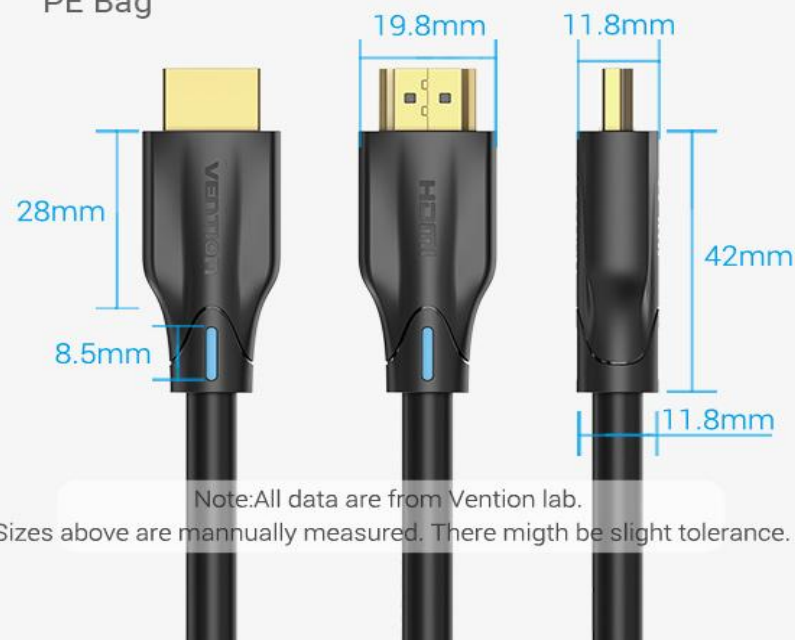



Note: Packing differs on lengths and batches, please take the actual packing as the standard.

Length	Art.No.	EAN Code
1M	AANBF	6922794743489
1.5M	AANBG	6922794743496
2M	AANBH	6922794743502
3M	AANBI	6922794743519
5M	AANBJ	6922794755147



Package Contents

HDMI 2.1 Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	100pcs(1m), 70pcs(1.5m), 60pcs(2m),50pcs(3m),35pcs(5m)
Carton Weight	10.6kgs(1m), 9.8kgs(1.5m), 11kgs(2m), 12.3kgs(3m),16kgs(5m)
Package	PE Bag

100	93	10.6
70	120.5	9.735
60	162	11.02
50	220	12.3
35	420.5	16.0175