



USB-C to USB OTG Cable

USB-C to USB OTG Cable

Support phone/tablet to flash disk/keyboard/mouse, etc.



Support OTG
Plug&Play

USB extension
for laptop

480Mbps
transmission rate

Design for
USB-C interface

Phone Connect to Flash Disk

Read file and watch movie without network



Music



Movie



Picture



Tablet Connect to Keyboard&Mouse

Optimal for mobile officing




Phone Connect to Gamepad

Turns your phone to mobile game console



Laptop USB Extension


Plug&Play for USB peripherals connection

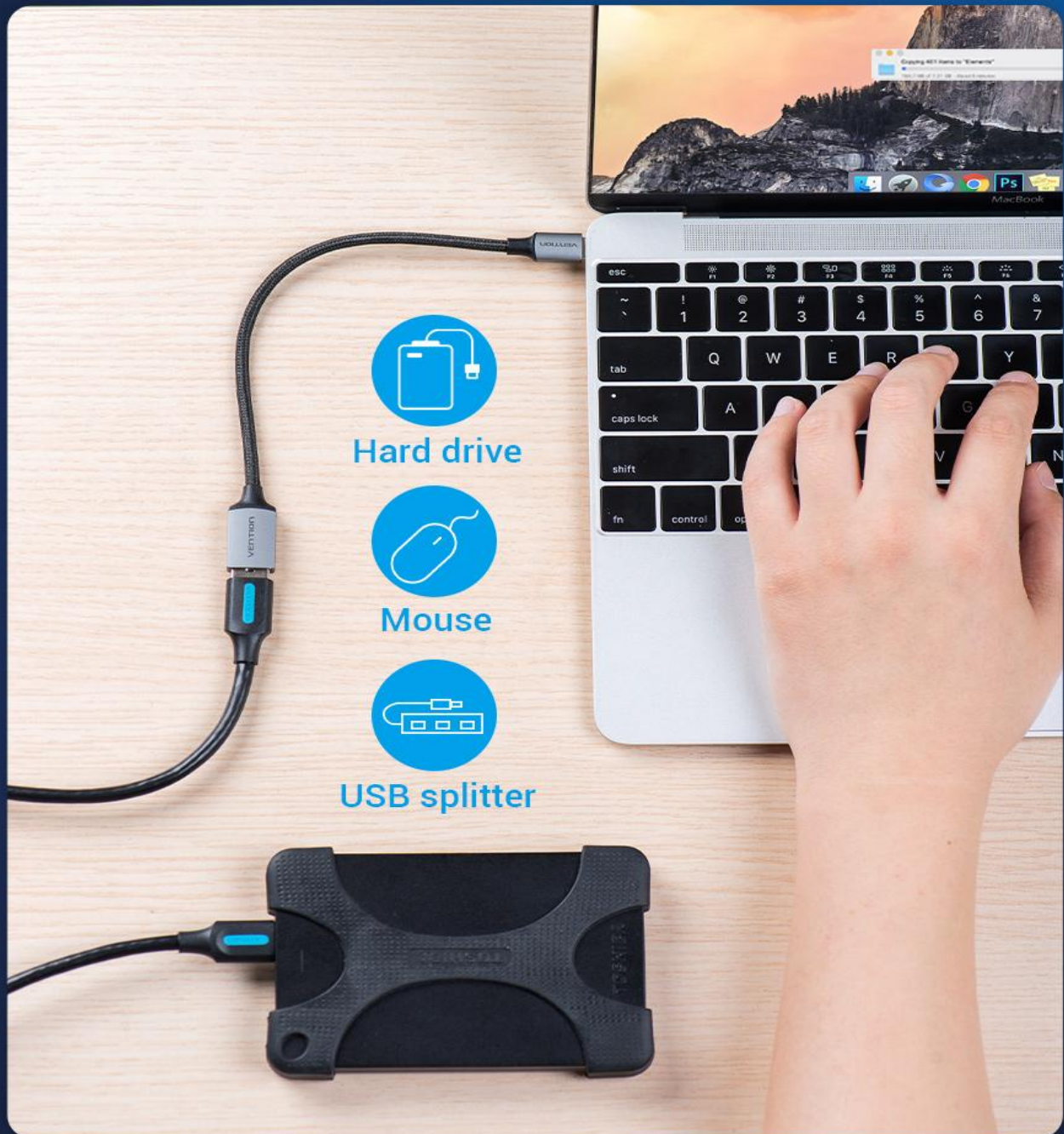

Fast Data Transmission

480Mbps theoretical transmission rate,
easily transfers picture and file


480Mbps

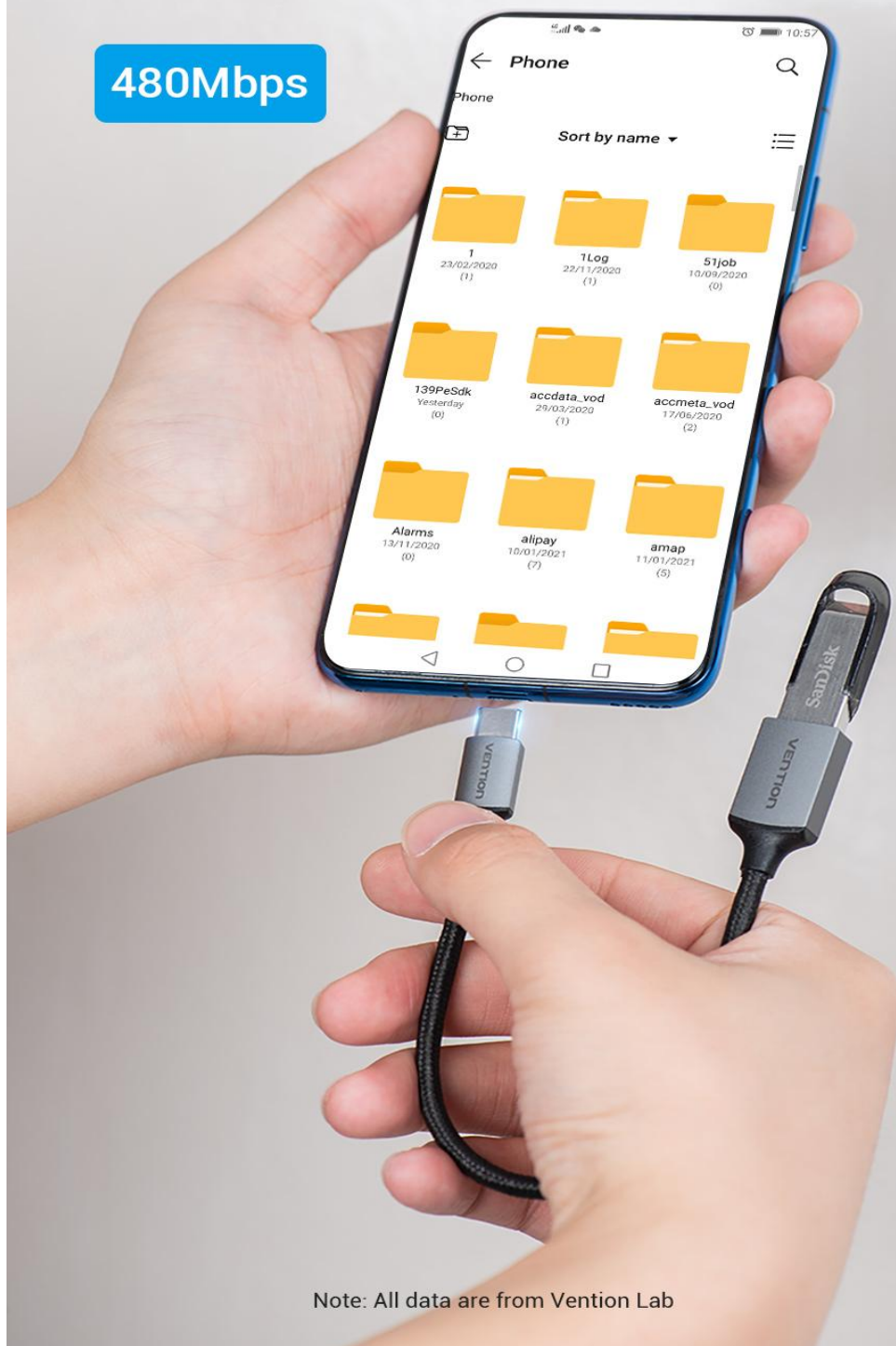

Note: All data are from Vention Lab

No lag and Latency

22+30AWG tinned-copper conductor with double shiedings for premium anti-interference ability

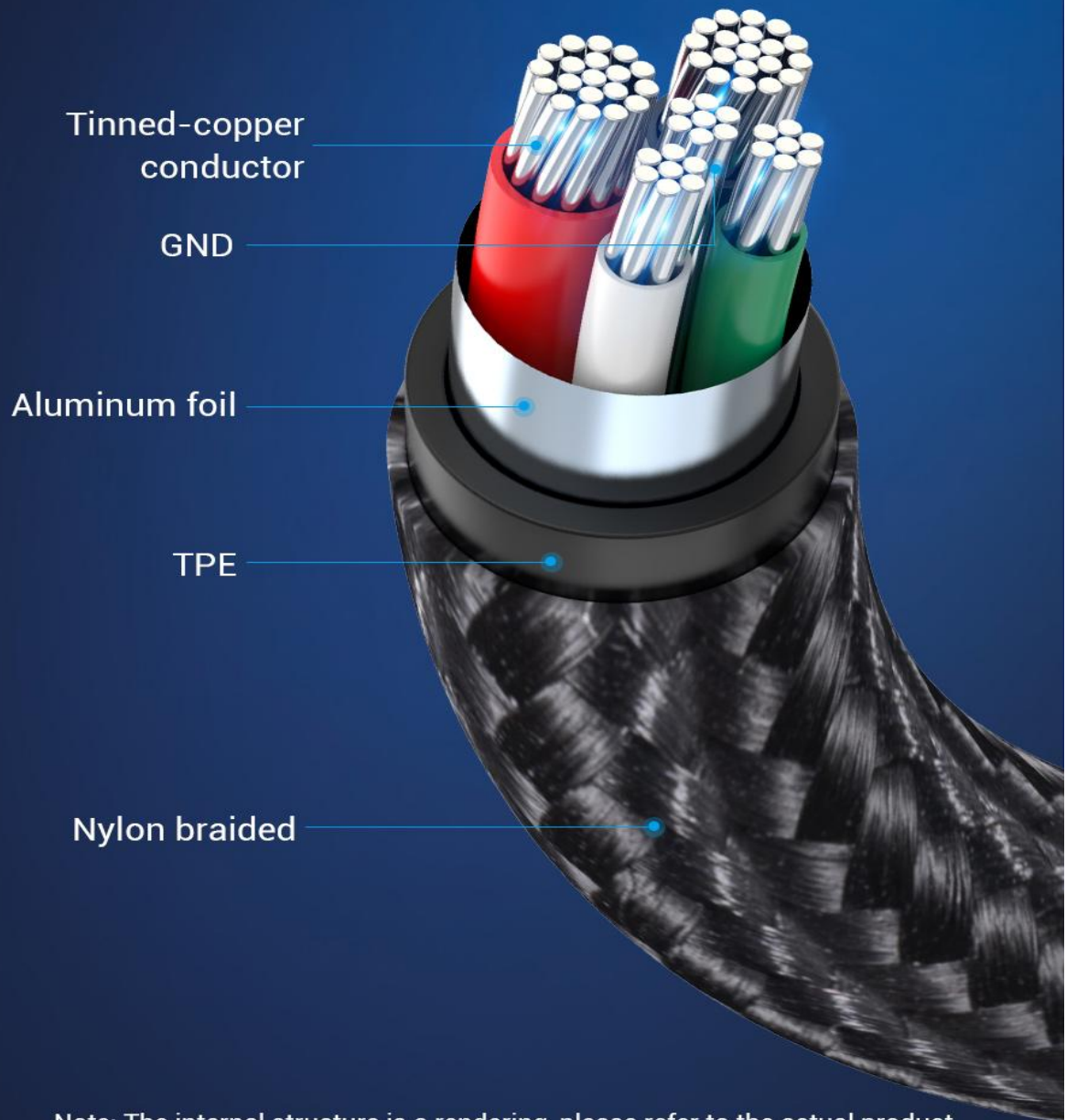

Note: The internal structure is a rendering, please refer to the actual product

Compatible Devices

Connect USB-A devices to USB-C devices



USB-C



Lightning



Micro



USB-A devices



Flash
disk



Mouse



Keyboard



Gamepad

.....

USB-C devices



Phone



Tablet



Computer

.....

Note: phone/tablet should support OTG function

Applicable USB-C Devices

	Laptop	Cellphone
Apple	MacBook12", MacBook Pro 2019 Mac Mini, MacBook Air 2020	Huawei Nova5/6/7 Mate20/30, Mate20/30 Pro Mate20/30 RS P20/30/40 P20/30/40 Pro
Huawei	MateBook, MateBook X/E MateBook 13/14	
Honor	MagicBook, MagicBook 2019	
Xiaomi	Air12.5"/13.3", GTX version 15.6" Xiaomi game book 8 generation	
HP	Pavilion x2, Spectre 13 EliteBook Folio G1, Envy 13 Shadow Wizard 4 Pro	Honor 30, 30S, V30 V20, Magic2 Note 10, V10
ASUS	Ling Yao 3, Ling Yao 3 Pro Ling Yao X series, U306, U321 U4100UN, U5100UQ, ROG	Microsoft Microsoft 950XL Microsoft 950
Dell	XPS13/15, Latitude 5285, G+C22 G3/G5/G7, Lingyue 5000/7000	Xiaomi 9/10 Pro, 9/10 8/9se, 8, 8 Lite Redmi Note7 Redmi K20/K30
Lenovo	Xiaoxin Air 12", Yoga5/6 Pro ThinkPad_X1 Carbon 2017 Saver Y7000/Y7000P/Y9000K	
SAMSUNG	NoteBook series GalaxyBook series	LG G5, V300L
Google	ChromeBook Pixels PixelBook Pen	Samsung S10, S10+, S10e A9s, A9 Stat Note8/9/10
Razer	Blade Stealth Spirit Blade Spirit Blade Sneak Edition	
Microsoft	Surface Book 2, Surface GO	Meizu 16/17th, X8
HTC	HTC 10	vivo Z5, iQOO, X27
Tablet	Apple iPad Pro 2018/2020	OPPO R17 Pro
	Huawei MediaPad M5	Smartisan Nut Pro 2S
	Xiaomi MI PAD 4	BlackShark BlackShark 2
More USB-C models will be continuously updated...		

Smooth Plug in/out

Tight conjunction for anti-loose purpose



Fast Recognition Instant Use

With no need to install driver



Longer Service Time

Avoid frequent cable changing

Nickel-plated interface

Anti-corrosion and wear resistance

Reinforced tail design

Durable in swapping

TPE&Nylon braided jacket

Tough and strong



Product Parameters

Brand: Vention

Name: USB 2.0 C Male to A Female OTG Cable

Model: CCWHB

Color: Gray

Interface: USB 2.0-A Female/USB 2.0-C Male

Interface Technics: Nickel-plated

Transmission Speed: 480Mbps

Conductor: Tinned-copper

Shell: Aluminum Alloy

Shielding: Aluminum Foil+GND

Jacket: TPE+Nylon Braided

AWG: 24+28AWG


OD: 4.3mm

Length: 0.15m

Power Supply: 2A

Warranty: 1 Year

Packing: PE Bag

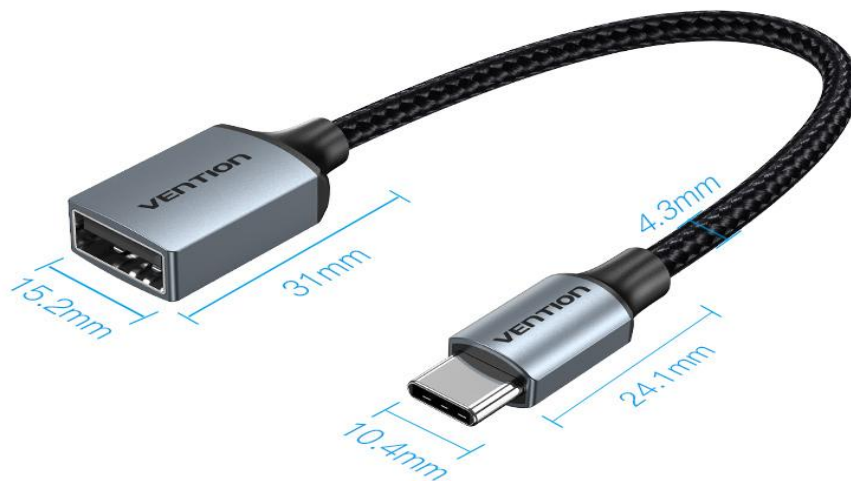

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance

Length	Art.No.	EAN Code
0.15m	CCWHB	6922794755062



Package Contents

USB-C to USB OTG Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*37*37cm
Carton Qty	500pcs
Carton Weight	8.3kgs
Package	PE Bag