

VGA(3+6) Cable

VGA (3+6) Cable

For HD Views



1080P
HD

Dual ferrite
cores

Gold-
plated

Pure copper
conductor

1080P HD Supported

1920*1080 pixels to show attractive views



Desktop Tower to Monitor

To be clear To be real




Dual Modes

01

Dual-screen Mirror Mode

Synchronic display of one view on two screens

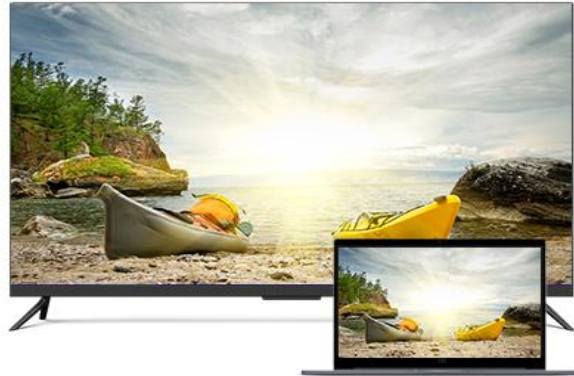

02


Dual-screen Expansion Mode

Individual views displayed on each screen for diversified needs



Dual Ferrite Cores for Anti-interference

Dual ferrite cores for outstanding anti-interference against EMI & RFI. And no more ripples

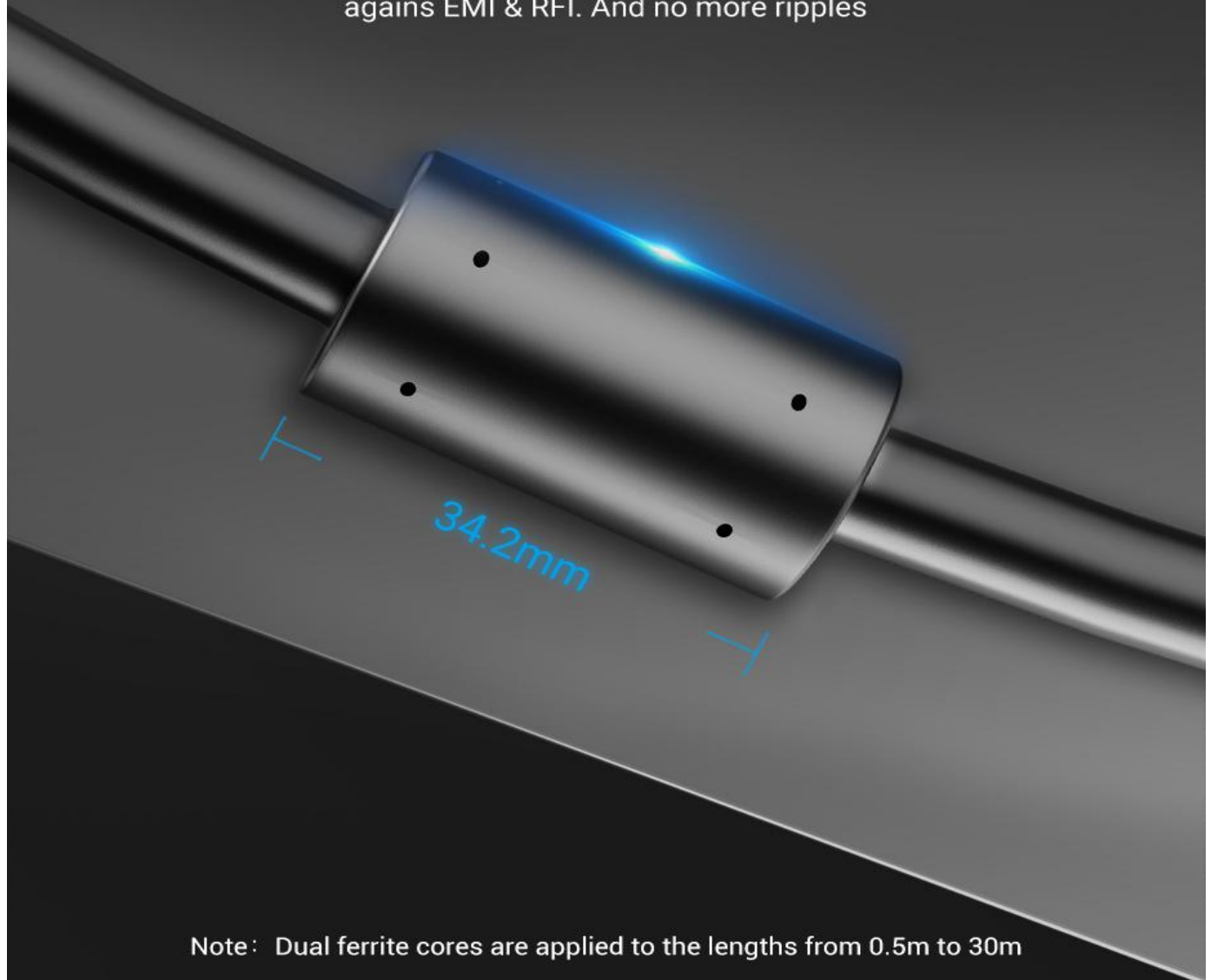

Note: Dual ferrite cores are applied to the lengths from 0.5m to 30m

Devices Supported

Applicable to output device and display device with VGA port




Gold-plated Interface

Resistant to abrasion, oxidation and rustiness



Shield Your Screen from Splash

Pure copper conductor for stable & fast signal transmission.

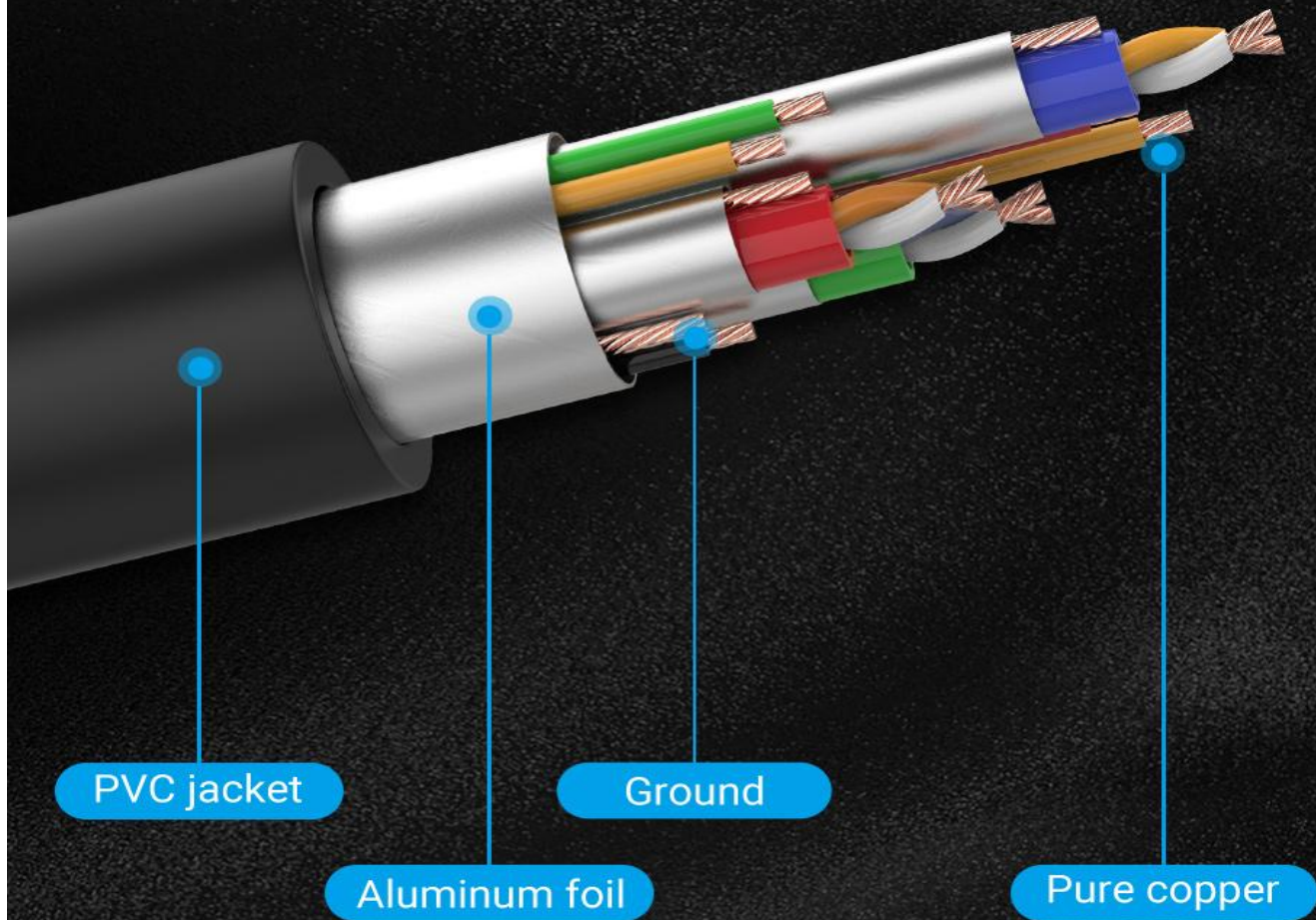

Multiple Lengths Available

Up to 30m transmission distance
for diversified requirements



Length	AWG	Ferrite core(s)	Resolution
0.5-5m	30AWG	Dual	1080P
8-15m	28AWG+30AWG	Dual	1080P
20-25m	28AWG+28AWG	Dual	1080P
30m	26AWG+28AWG	Dual	1080P

Product Parameters

Brand: Vention	Conductor: Pure Copper
Name: VGA (3+6) Cable	Shell: PVC
Model: DAE	Resolution: 1080P
Color: Black	Jacket: PVC
Connector: VGA Male	OD: 7.5mm
Interface: Gold-plated	Length: 0.5-30m
Shielding: Aluminun foil + Mag Ring	Warranty: 1Year
Transmission Direction: VGA Male to VGA Male	Packing: PE Bag/Carton
AWG: 0.5-5m: 30AWG 8-15m: 28AWG+30AWG 20-25m: 28AWG+28AWG 30m: 26AWG+28AWG	



Note: All data are from Vention lab
Sizes above are hand measurement, there might be slight tolerance



1-5m PE Bag



8-30m Carton

Note: Package differs on lengths and batches, please take the actual packing as the standard

Length	Art.No.	EAN Code
1m	DAEBF	6922794741607
1.5m	DAEBG	6922794741614
2m	DAEBH	6922794741621
3m	DAEBI	6922794741638
5m	DAEBJ	6922794741645
8m	DAEBK	6922794741652
10m	DAEBL	6922794741669
15m	DAEBN	6922794741676
20m	DAEBQ	6922794741683
25m	DAEBS	6922794741690
30m	DAEBT	6922794741706



Package Contents

VGA(3+6) Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm(0.5-5m), 46*40*40(8m), 52*46.5*24.5cm(10m,15m,20m), 48*29*30cm(25m,30m)
Carton Qty	50pcs(1.5m)
Carton Weight	10kg(1.5m)
Package	PE bag