



DP to VGA Cable

DP to VGA Cable

Desktop computer connect
to monitor/TV

HD
1080P

Gold-plated
interface

Double
shielding

Support
multiple modes



1080P HD

Support 1920*1080 resolution
video picture more delicate



Laptop Connect to TV

Watch movies on large screen more shocking



Large Screen Work More Efficiently

Laptop connect to projector
demonstration on large screen, work more efficiently





Fastener Design

DP interface adopts fastener design, connect solid




Note: Press the button first before pulling out

Excellent Details

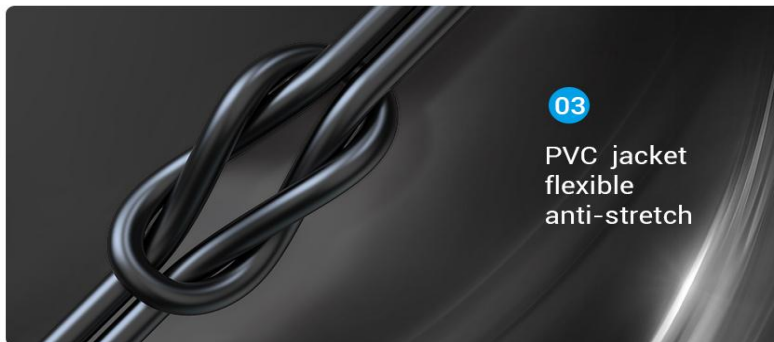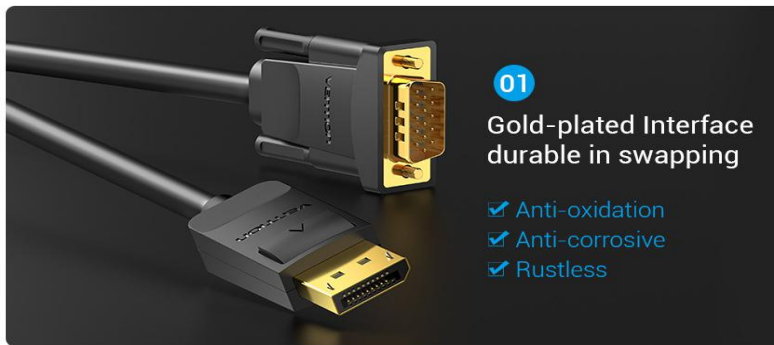

Double Shielding

Tinned-copper core + aluminum foil
+ metal braided double shielding, anti-splash

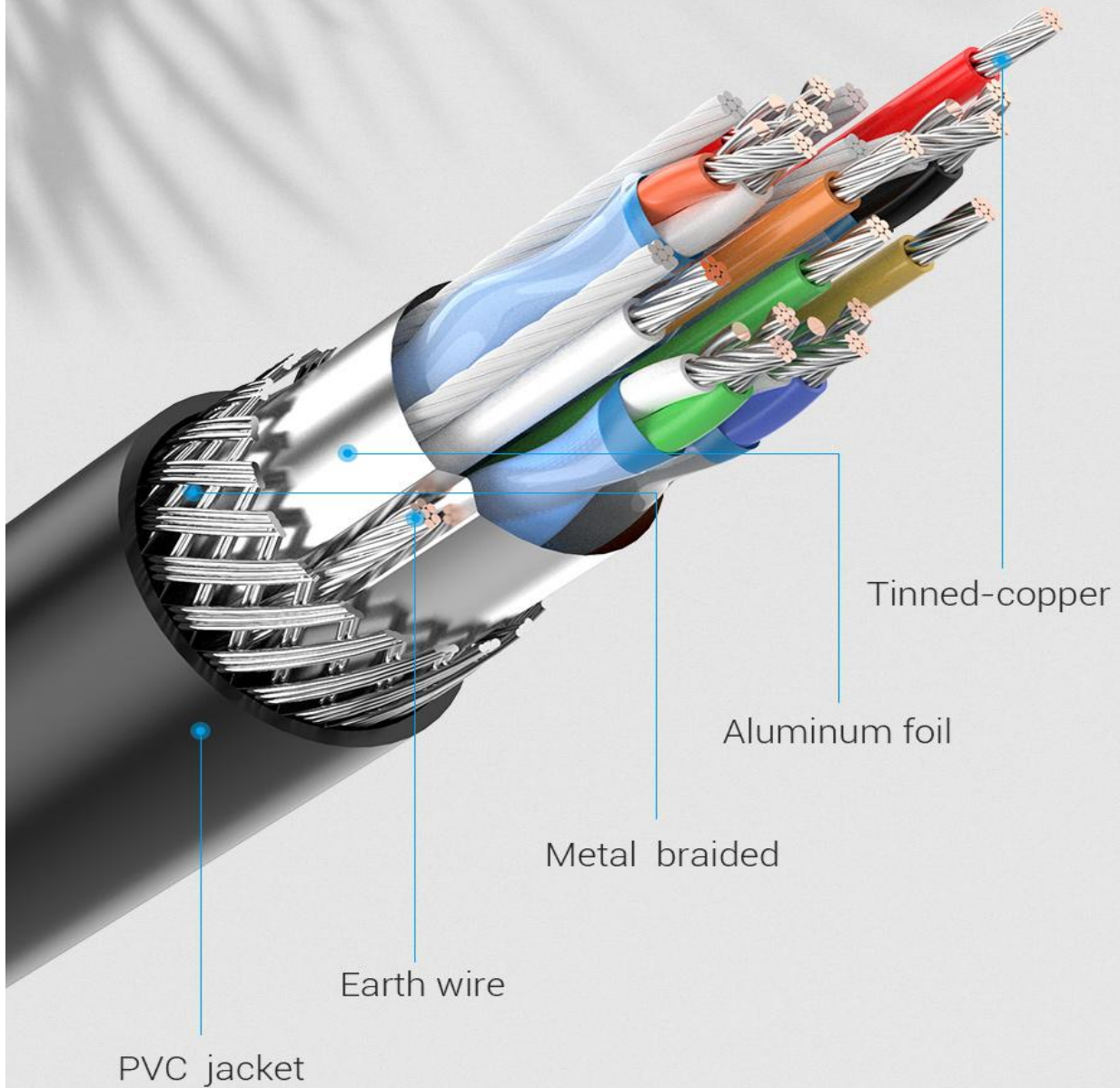

Chip Upgrade

Adopt ANX9833 chip, smooth playback



Note: The chip/PCB is a rendering
the internal structure is not fully displayed
please refer to the actual product

Multiple Modes

Copy mode

Display the same picture
larger screen
is more exciting



Expansion mode

Display the
different picture
work as well as play



Product Parameters

Brand: Vention

Name: DP to VGA Cable

Model: HBL

Color: Black

Interface: DP Male/VGA Male

Interface Technics: Gold-plated

Resolution: 1080P@60Hz

Conductor: Tinned-copper

Shell: DP-ABS VGA-PVC

Chip: ANX9833

Shielding: Aluminum Foil+Metal Braided

Jacket: PVC

AWG: 30AWG

OD: 7.0mm

Length: 1.5/2/3/5m

Warranty: 1 Year

Packing: PE Bag



Note: All data are from Vention Lab
Sizes above are manually measured. There might be slight tolerance



Note: Packing difference exists for different meters or batches.
The photo is for reference only

Length	Art.No.	EAN Code
1.5m	HBLBG	6922794746763
2m	HBLBH	6922794746770
3m	HBLBI	6922794746787
5m	HBLBJ	6922794746794



Package Contents

DP to VGA Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	70pcs(1.5m), 60pcs(2m), 45pcs(3m),30pcs(5m)
Carton Weight	10.24kg
Package	PE bag

www.ventioncable.com