




Cat.8 SFTP Patch Cable

Cat.8 SFTP Patch Cable

Vastly improve your LAN throughput

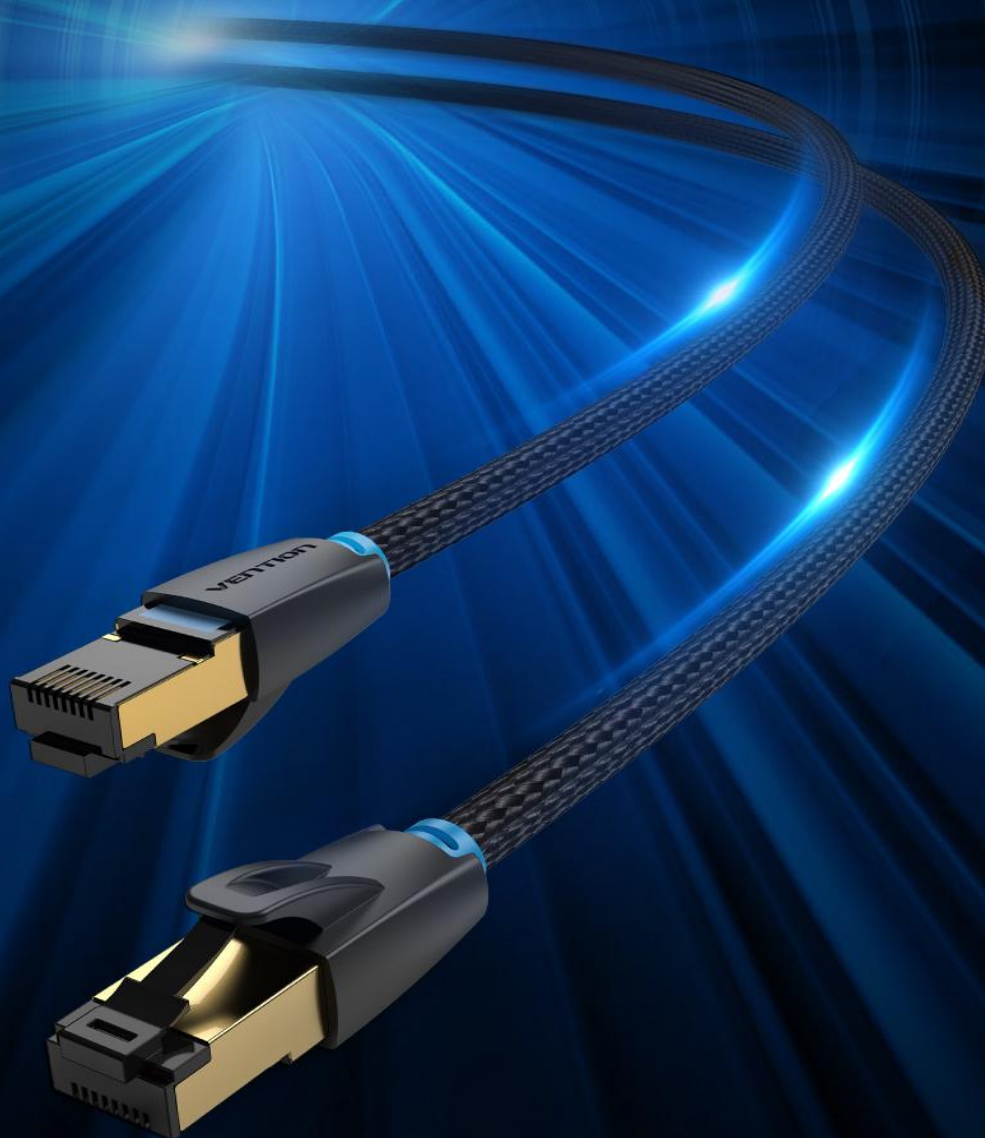

40Gbps



2000MHz



Pure copper
conductor



Double shield

40Gbps Transfer Rate

Work more efficiently



Stable
gaming



Fast
download



HD video
streaming



Note: All data are from Vention Lab

The Coming 5G Era

Type	Rate	Bandwidth	Distance	Cable type	Application
Cat.8	40Gbps	2000MHz	30m	Double shield	High-speed bandwidth environment
Cat.7	10Gbps	600MHz	100m	Double shield	High-speed bandwidth environment
Cat.6A	10Gbps	500MHz	100m	Shielded / Unshielded	Large enterprises / High-speed applications
Cat.6	1000Mbps	250MHz	100m	Shielded / Unshielded	Large enterprises / High-speed applications
Cat.5e	100Mbps	155MHz	100m	Shielded / Unshielded	Small Office / Home
Cat.5	100Mbps	100MHz	100m	Shielded / Unshielded	Small Office / Home


Note: The actual use data may be restricted by the environment of routers switches, network providers and other equipments

Five Upgrades

Upgrade 1

Bold Pure Copper Conductor

Ensures high performance

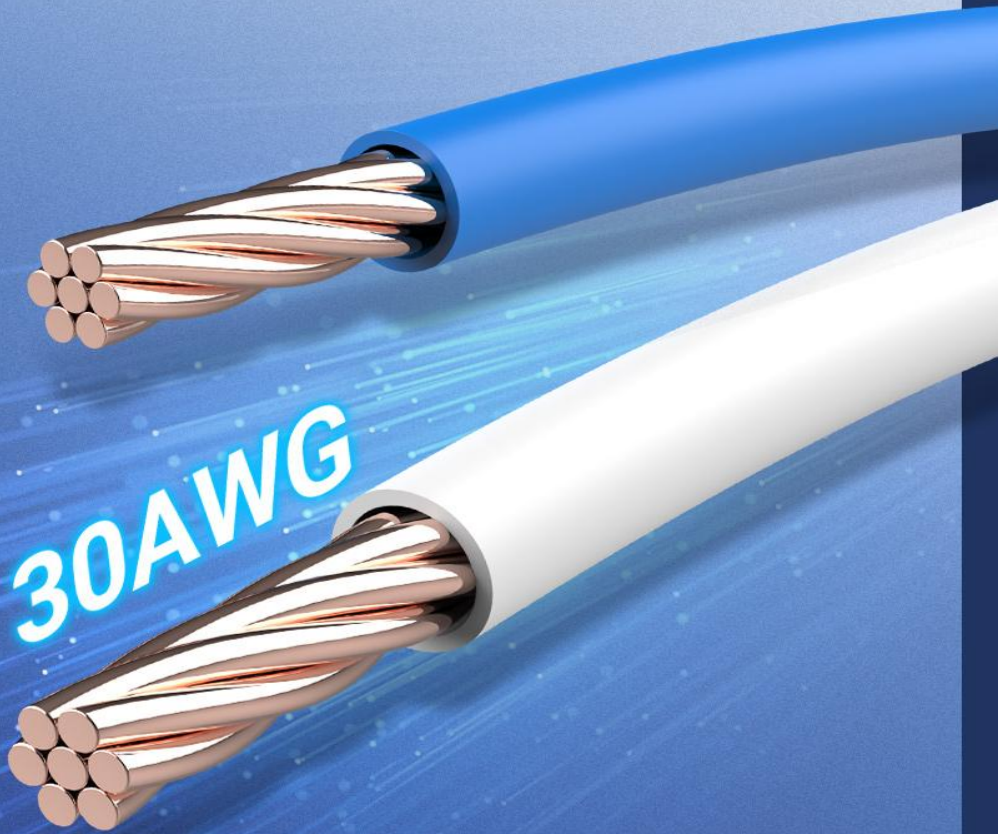


Note: The internal structure is a rendering
please refer to the actual product

Upgrade 2

Double Shield

Stable network

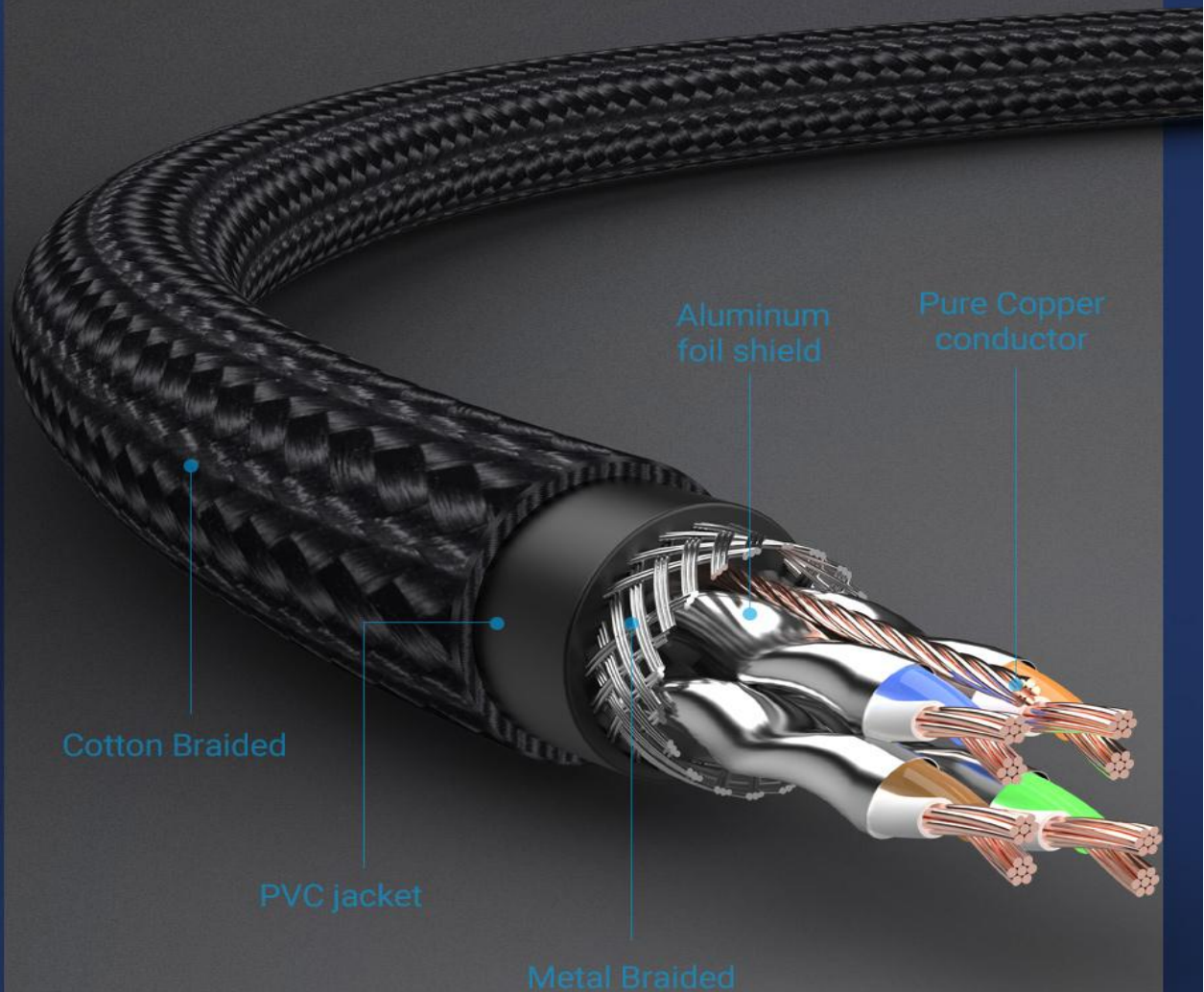

Note: The internal structure is a rendering
please refer to the actual product

Upgrade 3

Wear-resistant RJ45 Plug 10000 Times Swapping Test

Gold-plated
copper shell

Enhanced ramp
protector

VENTION®

Note: All data are from Vention Lab

Upgrade 4

Gold-plated Contacts

Wear-resistant and significantly enhance transmission speed



50U Golden contacts



Upgrade 5

Long Service Life

PVC+cotton braided jacket, more durable



Cotton braided



Flexible

Multiple Devices&Application



Desktop



Laptop



Router



Switch



TV



TV box



Digital printer



Home / Office



Internet Cafe
/ Community



Supermarket
/ Department



KTV / Club




Hotel



School / Building

FLUKE Networks Test

Meet the Cat.8 network cable standards

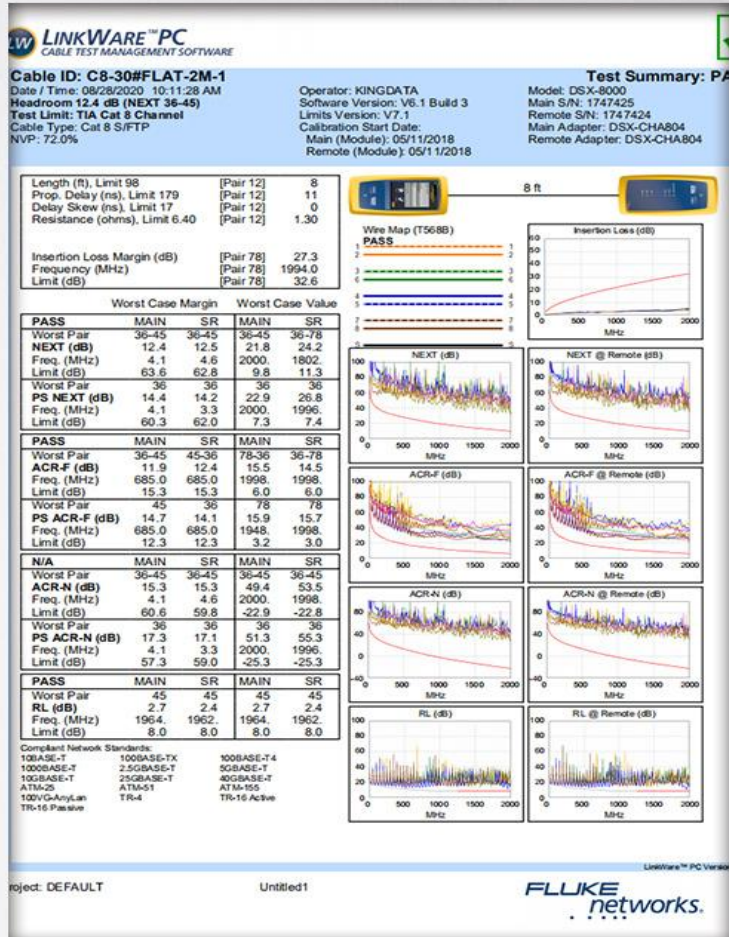

Product Parameters

Brand: Vention

Name: Cat.8 SFTP Patch Cable

Model: IKG

Color: Black

Interface: RJ45

Transmission Rate: 40Gbps

Transmission Bandwidth: 2000MHz

Shield Shell: Gold-plated Copper Shell

Connector Chips Technics: Gold-plated 50U Trigeminal Chip

Conductor: Pure Copper

Shielding: Aluminum Foil+Metal Braided

Jacket: PVC+Cotton Braided


AWG: 30AWG

OD: 5.5mm

Length: 0.5/1/1.5/2/3/5/8m

Warranty: 1 Year

Packing: PE Bag

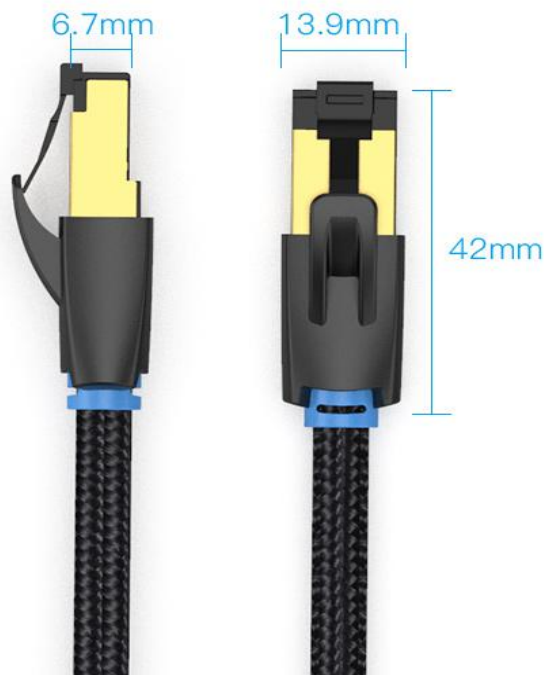

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance



Note: Packing difference exists for different meters or batches.
The photo is for reference only.

Length	Art.No.	EAN Code
0.5m	IKGBD	6922794749627
1m	IKGBF	6922794749634
1.5m	IKGBG	6922794749641
2m	IKGBH	6922794749658
3m	IKGBI	6922794749665
5m	IKGBJ	6922794749672
8m	IKGBK	6922794749689



Package Contents

Cat.8 SFTP Patch Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	200pcs(0.5m), 160pcs(1m), 140pcs(1.5m), 120pcs(2m), 80pcs(3m), 60pcs(5m), 50pcs(8m)
Carton Weight	7.8kgs(0.5m), 8.42kgs(1m), 9.14kgs(1.5m), 9.46kgs(2m), 8.98kgs(3m), 9.88kgs(5m), 12.1kgs(8m)
Package	PE Bag

www.ventioncable.com