



USB 3.0 Extension Cable

USB3.0

Extension Cable



Super Speed



Nickel-plated
Interface



Triple shield

Extend Charger Cable

You can charge while playing with your phone



Computer Interface Extension

More convenient to engage in your work





U Disk Connect to TV

Enjoy entertainment of big screen


Flat Cable

Easier to lay in a narrow space



Exquisite Workmanship

Triple shielding anti-interference

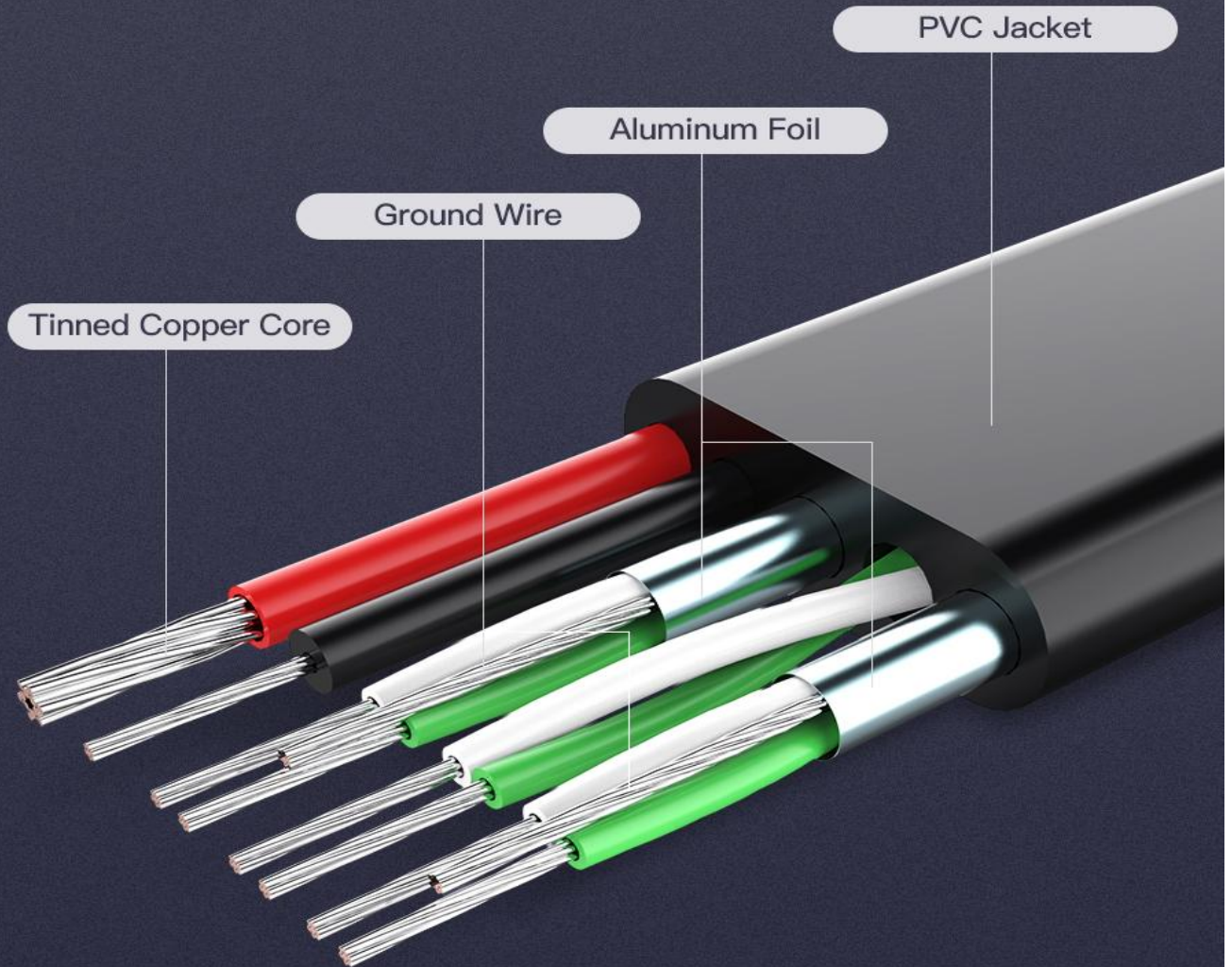

Durable Nickel-plated Interface

Corrosion resistance,no rust,reduce transmission loss






Two-color Injection Molded Plug Housing

Comfortable to handle, easy to insert and pull, durable



Widely Applicable

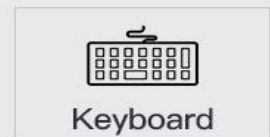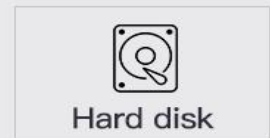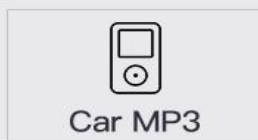

Product Parameters

Brand	Vention
Name	USB3.0 Extension Cable
Model	VAS-A13
Color	Black/White
Type	USB Male, USB Female
Version	USB3.0
Theoretical Speed	5Gbps
Connector	Nickel-plated
Conductor	Tinned Copper Core
Jacket	PVC
OD	2.8*8.5mm
Length	0.5m/1m/1.5m/2m/3m
AWG	30AWG+24AWG
Warranty	1 Year
Package	PE Bag

PS: All data are from Vention laboratory



PS: Sizes above are hand measurement there might be slight tolerance



PS: Sizes above are hand measurement there might be slight tolerance

Length	Art.No.	EAN Code
0.5m	VAS-A13-B050	6922794719361
1m	VAS-A13-B100	6922794719378
1.5m	VAS-A13-B150	6922794719385
2m	VAS-A13-B200	6922794719392
3m	VAS-A13-B300	6922794719408



Package Contents

USB 3.0 Extension Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	300pcs(0.5m,1m), 200pcs(1.5m), 150pcs(2m,3m), 150pcs(2m),100pcs(3m)
Carton Weight	15.5kgs(1.5m)
Package	PE Bag