

Application

Automotive Grade

Series

FA28

Dimensions

L	
W	5.5mm Max.
T	2.5mm Max.
F	5mm +/-1mm
d	0.5mm +0.1,-0.03mm

Temperature Characteristic

-55 to 125°C 0+/-30ppm/°C

Rated Voltage

100Vdc

Capacitance

10nF

Capacitance Tolerance

+/-5%

Q Factor

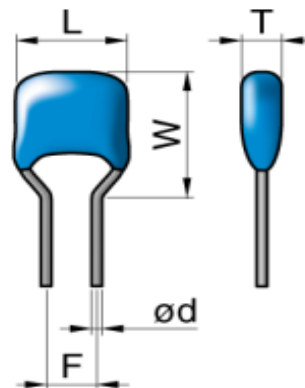
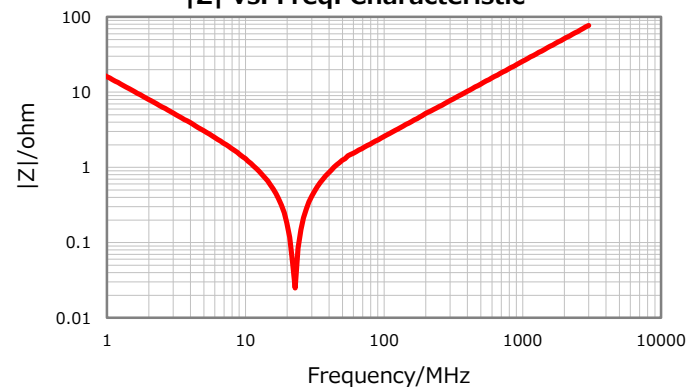
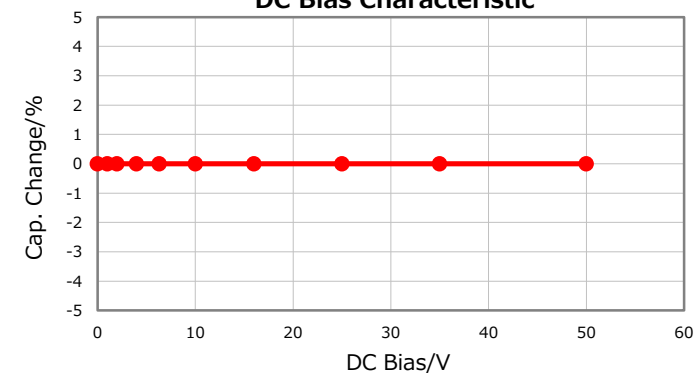
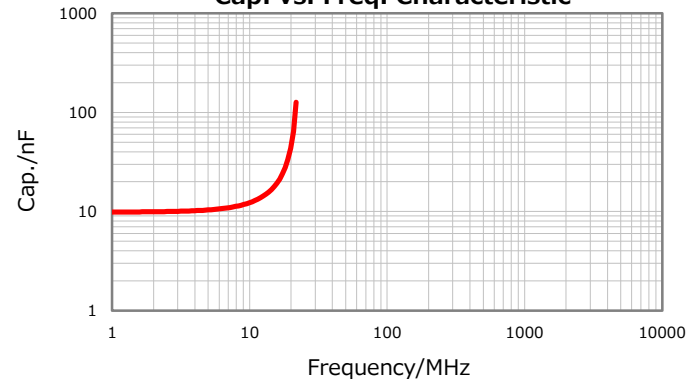
1000 Min

Insulation Resistance

10000Mohm Min.

AEC-Q200

YES

**|Z| vs. Freq. Characteristic****DC Bias Characteristic****Cap. vs. Freq. Characteristic****Temperature Characteristics**