

Technical data sheet

SurgeController V20, plug-in arrester, leak current-free

Item no. 5099613




Separate cover (plug-in).

- Suitable for use in pre-meter area (completely leakage current-free)
- Plug-in cover; cover can be separated from base without tools



Dimensions

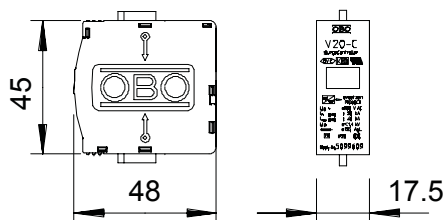

Master data

Item no.	5099613
Type	V20-VA 0
Description 1	SurgeController V20
Description 2	leakage current free, upper
Dimension	385V
Smallest sales unit (VG)	1,00 Piece
Weight	6,02 kg/100 pc.


Technical data sheet

SurgeController V20, plug-in arrester, leak current-free

Item no. 5099613



Technical data

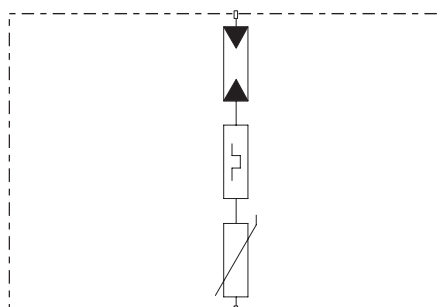

SPD to EN 61643-11	Type 2
SPD to IEC 61643-11	Class II
Maximum continuous voltage AC	385,00 V
Max. continuous operating voltage	385,00 V
Nominal discharge current (8/20)	20 kA
Maximum discharge current (8/20 µs)	25,00 kA
Protection level	< 1,8 kV
Response time	< 100 ns
Maximum back-up fuse	125,00 A
Temperature range	-40-+80 °C
Pole version	1
Version	1-pole cover; 385 V
Version	1-pole
Mounting type	On basic element
Installation type	On basic element
Protection rating	IP20
Protection rating	IP 20
Blow-out	☐
Division unit TE (17.5 mm)	1
Remote signalling	☐
Telecommunications contact	☐
Signalling on device	Visual