

Product family: Brass cable glands - Gas thread


Item code: 2460, 2461, 2462, 2463, 2464, 2465, 2466, 2467, 2468, 2469, 24692, 24693

Description: ACCESSORIES FOR BRASS CABLE GLANDS: GAS THREAD · HEXAGONAL LOCKNUTS

Image



Technical drawing

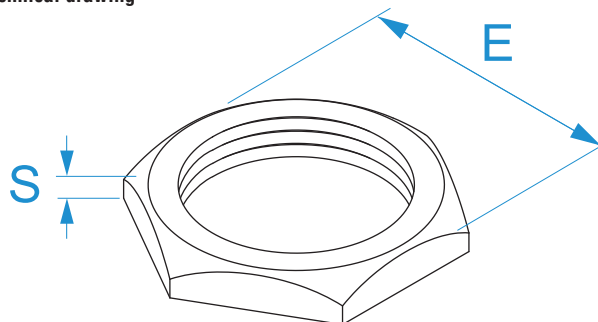

Specifications

MATERIAL: nickel-plated brass

OPERATING TEMPERATURE: from -20 °C to +70 °C

Code	Gas thread (ISO228/1)	E wrench (nut)	S (mm)	
2460	G 1/4"	15	2,8	100/100
2461	G 3/8"	19	3,2	
2462	G 1/2"	24	3,75	
2463	G 5/8"	26	3,75	
2464	G 3/4"	30	4	50/50
2465	G 1"	37	4,5	
2466	G 1 1/8"	42	5	
2467	G 1" 1/4"	46	5	25/25
2468	G 1" 1/2"	54	5,5	20/20
2469	G 2"	65	5,7	
24692	G 2 1/2"	80	7	5/5
24693	G 3"	95	8	10/10