



Technical sheet

No.


11FA10A

Issue

V01.0

Product family: Cable-ties - Nylon cable-ties UV resistant
Item code: N1890, N2690, N3690
Description: NYLON CABLE TIES UV RESISTANT - IMPACT RESISTANT

Image

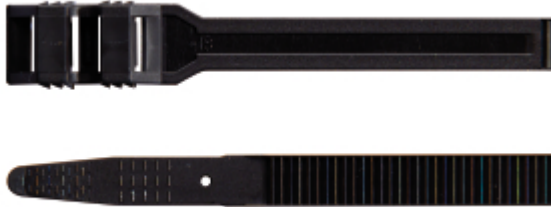

Specifications

MATERIAL: polyamide (PA 6.6) + carbon black
COLOR: black
INSULATION SELF-EXTINGUISHING: UL 94 V2
OPERATING TEMPERATURE: from -40 °C to +85 °C
MINIMUM INSTALLATION TEMPERATURE: -10 °C
CHEMICAL RESISTANCE: good resistance to bases, oils, grease, chloride solvents. Limited resistance to acids. Not resistant to phenols.
ACCORDING TO STD.: EN 62275:2015-02
CLASSIFICATION: type 1 (EN)
ASSEMBLY: open the package just before use

Code	Width (mm)	Length (mm)	Max bundle Ø (mm)	Min bundle Ø (mm)	Tensile minimum resistance (N)	
N1890	9	180	40	20	400	100/1500
N2690	9	265	62	20	540	100/1400
N3690	9	360	93	20	540	100/500



**HALOGEN
FREE**

**UV
RESISTANT**