


Dual color 2835 LED Tape Light

240 LED/M

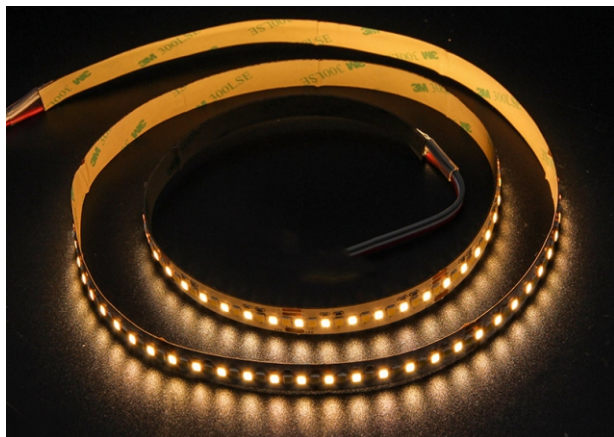

Product Description:


High density CCT color Adjustable LED strip has
 240pcs 2835 LEDs
 With 12mm Width, 2 Ounce copper
 Cut-able every 12LEDs & 50mm
 All soldering Pads are very large, allowing you to
 easily cut and reconnect
 DC24V constant voltage operation
 Both ends have 3pin bare wires for powering
 3M tape attached on backside of FPC
 5 meters per reel,
 Waterproof types IP20, IP65



Product Datasheet

Product Number	S012240BC2PZ	Luminance/M	CW:900 WW:901lm
Operating Voltage	DC24V	Ra	/
Power/M	19.2W	Beam Angle	120°
SMD Type	2835	Size (mm)	5000 * 12mm
LED Qty/M	240	IP Rate	IP20/IP65
Color	2800-3200K+6000-6500K	Operation Temperature	- 25 ~ 60 °C
Pixel/M	/	Material	FPC
Control	PWM	Cutting Length	50mm
Wavelength	/	Net Weight/Roll	0.215kg


Outline Dimension (unit: mm)

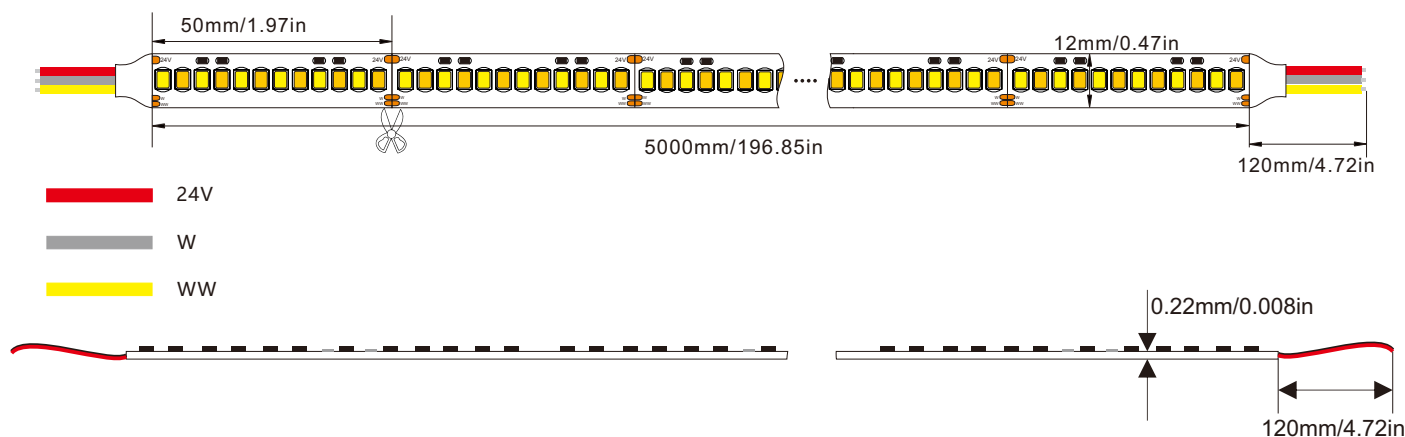

◆ Order number

DC24V	3000K+6000K	White PCB	IP20	S012240BC2PZ/C1
DC24V	3000K+6000K	White PCB	IP65	S012240BC2PZ/C2
DC24V	3000K+6000K	Black PCB	IP20	S012240BC2PZ/C3
DC24V	3000K+6000K	Black PCB	IP65	S012240BC2PZ/C4

◆ Wiring diagram

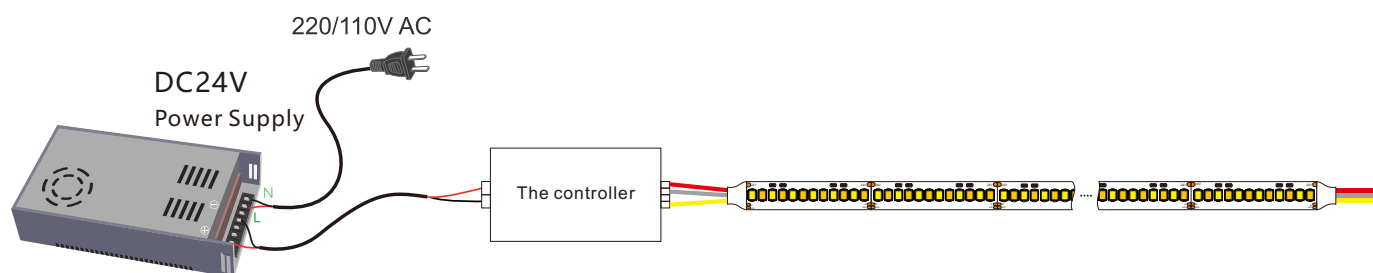

◆ Strip IP Rate



◆ Accessories



Screw




Silicone clip




End cap


◆ Schematic diagram of maximum bending prevention

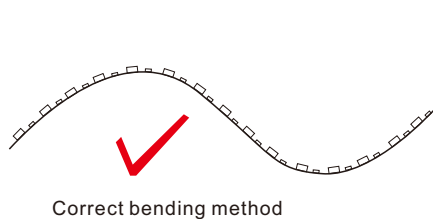

Correct bending method

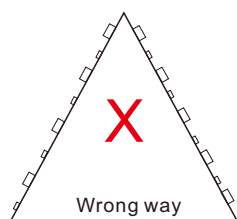

Wrong way

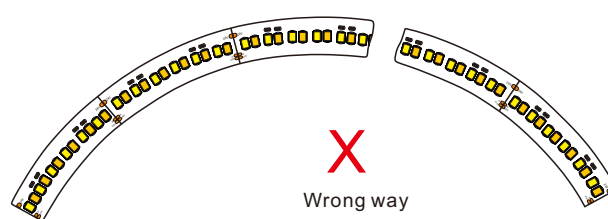

Wrong way

Note: The parameters are subject to change without notice!