



USB-C to USB 3.0 OTG Cable

More variability for USB-C

USB-C to USB 3.0 OTG Cable

Support phone/tablet
to flash disk/keyboard/mouse, etc.



Support OTG
Plug&Play

USB extension
for laptop

5Gbps
transmission rate

Design for
USB-C interface

Phone Connect to Flash Disk

Read file and watch movie without network



Music



Movie



Picture



USB Peripherals Connection


Optimal for mobile officing



Mouse



Keyboard

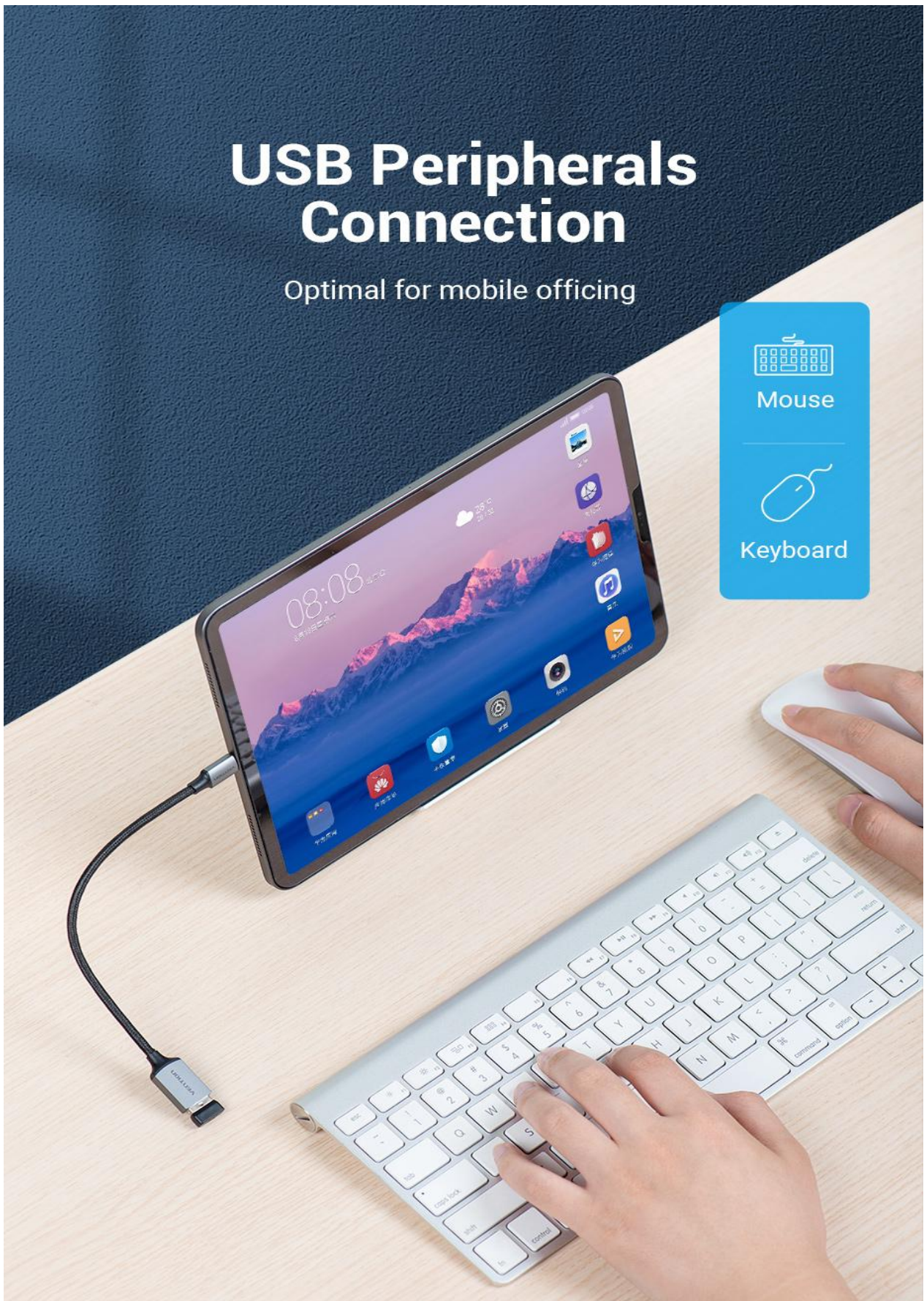

Enhanced Game Experience

Turns your phone to mobile game console



Gamepad



Laptop USB Extension

Plug&Play for USB peripherals connection



Hard drive



Mouse




USB splitter



1GB File within 5 Sec.

Standard USB 3.0 interface
with a theoretical rate of 5Gbps

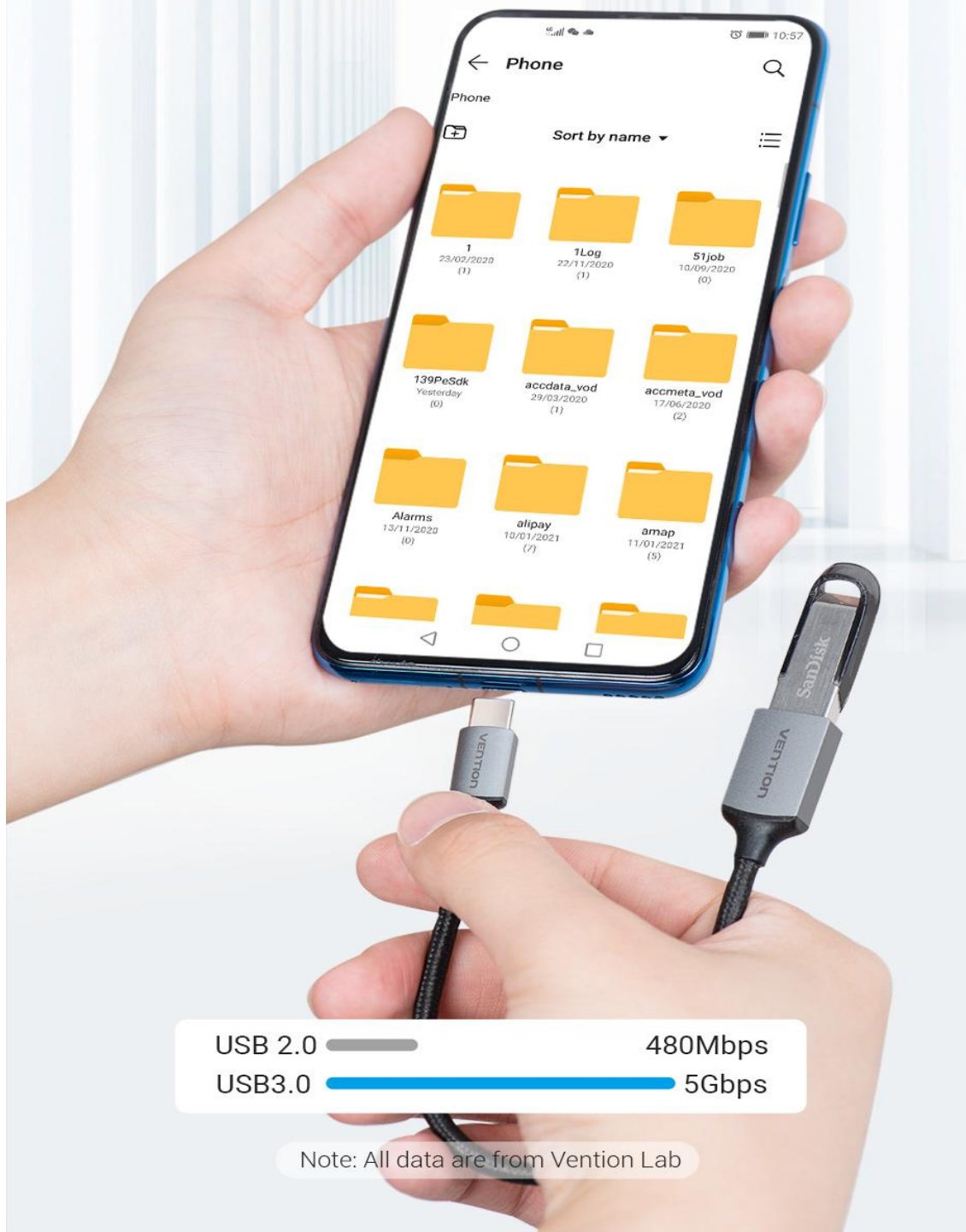

No lag and Latency

22+30AWG tinned-copper conductor
with double shiedings for premium anti-interference ability

Tinned-copper conductor


GND

Aluminum foil

Metal braided

TPE

Nylon braided

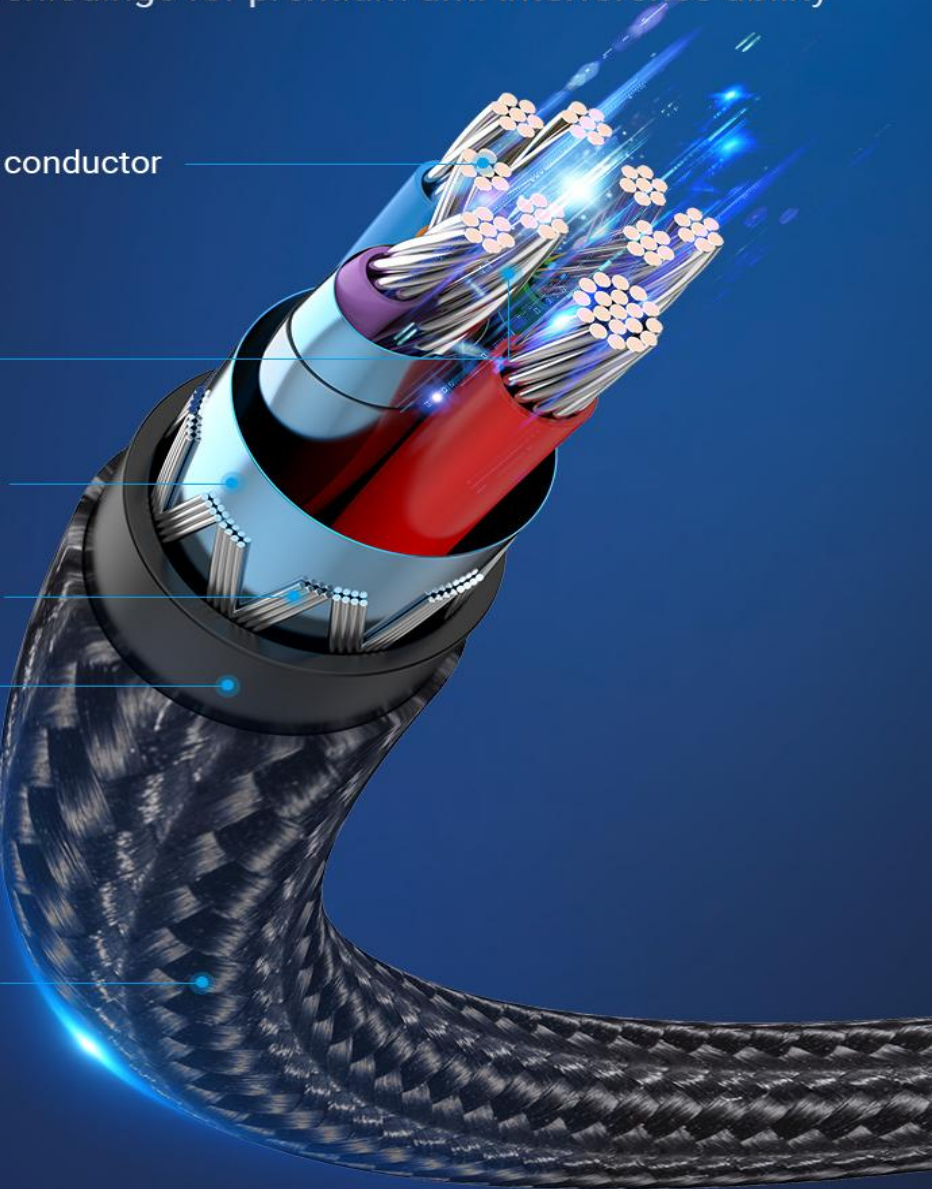

Note: The internal structure is a rendering
please refer to the actual product

Compatible Devices

Connect USB-A devices to USB-C devices



USB-C



Lightning



Micro



USB-A devices



Flash disk



Keyboard



Mouse



Game console

.....

USB-C devices



Phone



Tablet



Computer

.....

Note: phone/tablet should support OTG function

Applicable USB-C Devices

	Laptop	Cellphone
Apple	MacBook12", MacBook Pro 2019 Mac Mini, MacBook Air 2020	Huawei Nova5/6/7 Mate20/30, Mate20/30 Pro Mate20/30 RS P20/30/40 P20/30/40 Pro
Huawei	MateBook, MateBook X/E MateBook 13/14	
Honor	MagicBook, MagicBook 2019	
Xiaomi	Air12.5"/13.3", GTX version 15.6" Xiaomi game book 8 generation	
HP	Pavilion x2, Spectre 13 EliteBook Folio G1, Envy 13 Shadow Wizard 4 Pro	Honor 30, 30S, V30 V20, Magic2 Note 10, V10
ASUS	Ling Yao 3, Ling Yao 3 Pro Ling Yao X series, U306, U321 U4100UN, U5100UQ, ROG	Microsoft Microsoft 950XL Microsoft 950
Dell	XPS13/15, Latitude 5285, G+C22 G3/G5/G7, Lingyue 5000/7000	Xiaomi 9/10 Pro, 9/10 8/9se, 8, 8 Lite Redmi Note7 Redmi K20/K30
Lenovo	Xiaoxin Air 12", Yoga5/6 Pro ThinkPad_X1 Carbon 2017 Saver Y7000/Y7000P/Y9000K	
SAMSUNG	NoteBook series GalaxyBook series	LG G5, V300L
Google	ChromeBook Pixels PixelBook Pen	Samsung S10, S10+, S10e A9s, A9 Stat Note8/9/10
Razer	Blade Stealth Spirit Blade Spirit Blade Sneak Edition	
Microsoft	Surface Book 2, Surface GO	Meizu 16/17th, X8
HTC	HTC 10	vivo Z5, iQOO, X27
Tablet	Apple iPad Pro 2018/2020	OPPO R17 Pro
	Huawei MediaPad M5	Smartisan Nut Pro 2S
	Xiaomi MI PAD 4	BlackShark BlackShark 2
More USB-C models will be continuously updated ...		

Smooth Plug in/out

Tight conjunction for anti-loose
purpose during connection



Fast Recognition Instant Use

With no need to install driver



Longer Service Time

Avoid frequent cable changing

Reinforced tail design

Durable in swapping

Nickel-plated interface

Anti corrosion
and wear resistance

TPE&Nylon braided jacket

Tough and strong



Product Parameters

Brand: Vention

Name: USB 3.0 C Male to A Female OTG Cable

Model: CCXHB

Color: Gray

Interface: USB 3.0-A Male/USB 3.0-C Female

Interface Technics: Nickel-plated

Transmission Speed: 5Gbps

Conductor: Tinned-copper

Shell: Aluminum Alloy

Shielding: Aluminum Foil+Metal Braided+GND

Jacket: TPE+Nylon Braided

AWG: 22+30AWG


OD: 4.3mm

Length: 0.15m

Power Supply: 2A

Warranty: 1 Year

Packing: PE Bag

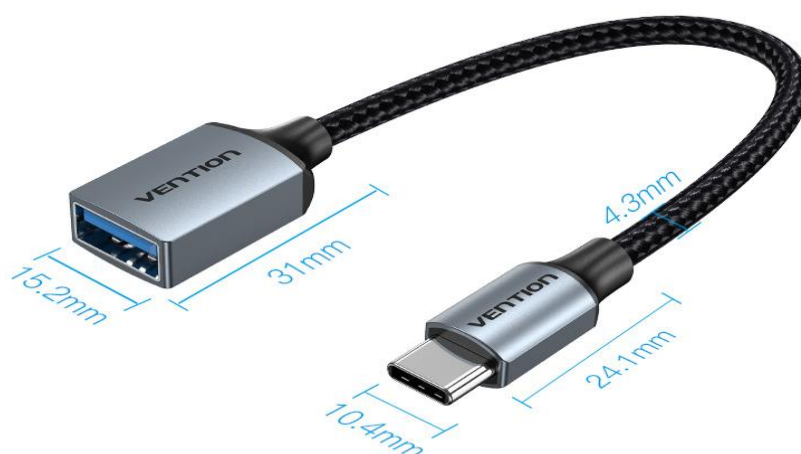

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance

Length	Art.No.	EAN Code
0.15m	CCWHB	6922794755062



Package Contents

USB-C to USB 3.0 OTG Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	500pcs
Carton Weight	8.3kgs
Package	PE Bag