



CAT 5E UTP Patch Cable



CAT5E UTP Patch Cable

100Mbps
transmission

Stable
surfing

Bold
core

Twisted pair
anti-jamming

Not Stuck



No delay
in games



Download
faster




Smoother
viewing



Range of Application

Universal RJ45 cable interface

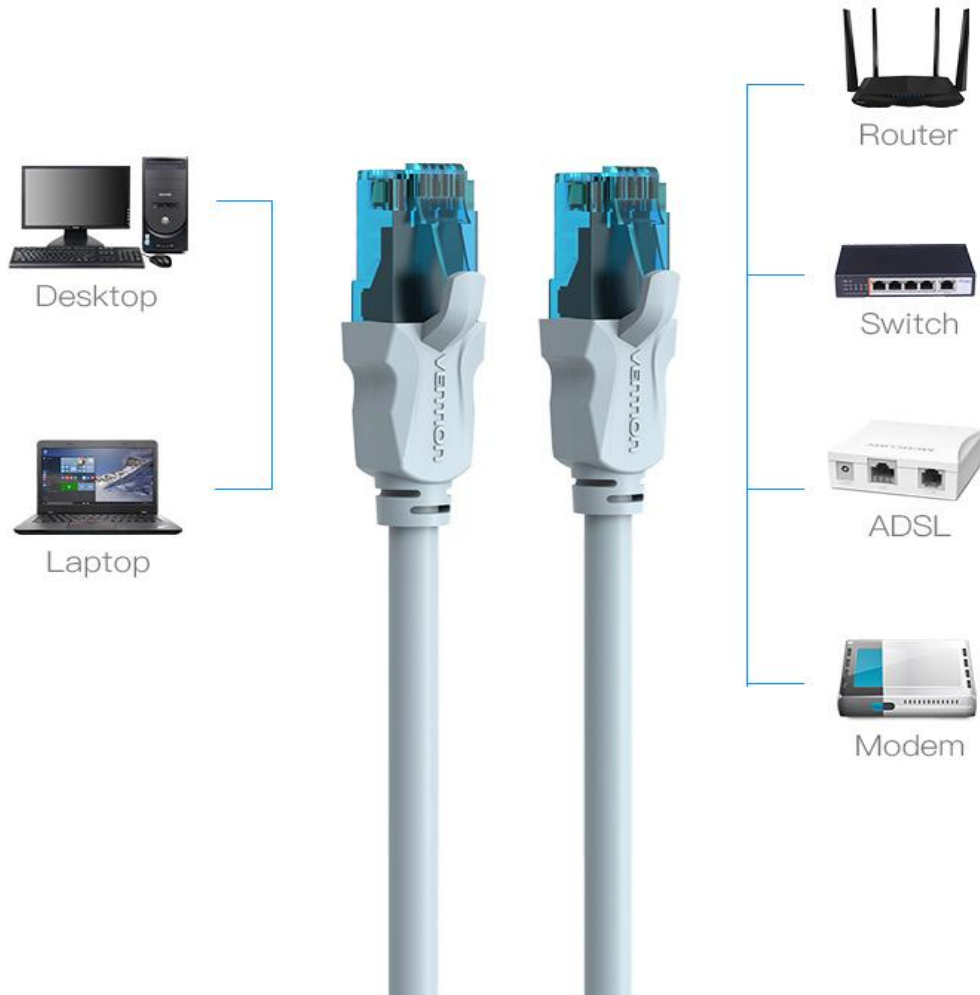




Stable and Uninterrupted

Each core is composed of 7 independent cores composed of multiple conductive low resistance, 26AWG bold copper-clad aluminum core with copper load and low aluminum density

Twisted Pair Anti-jamming

8-core twisted structure, each 2 cores are twisted with each other
Resist against electromagnetic interference from outside

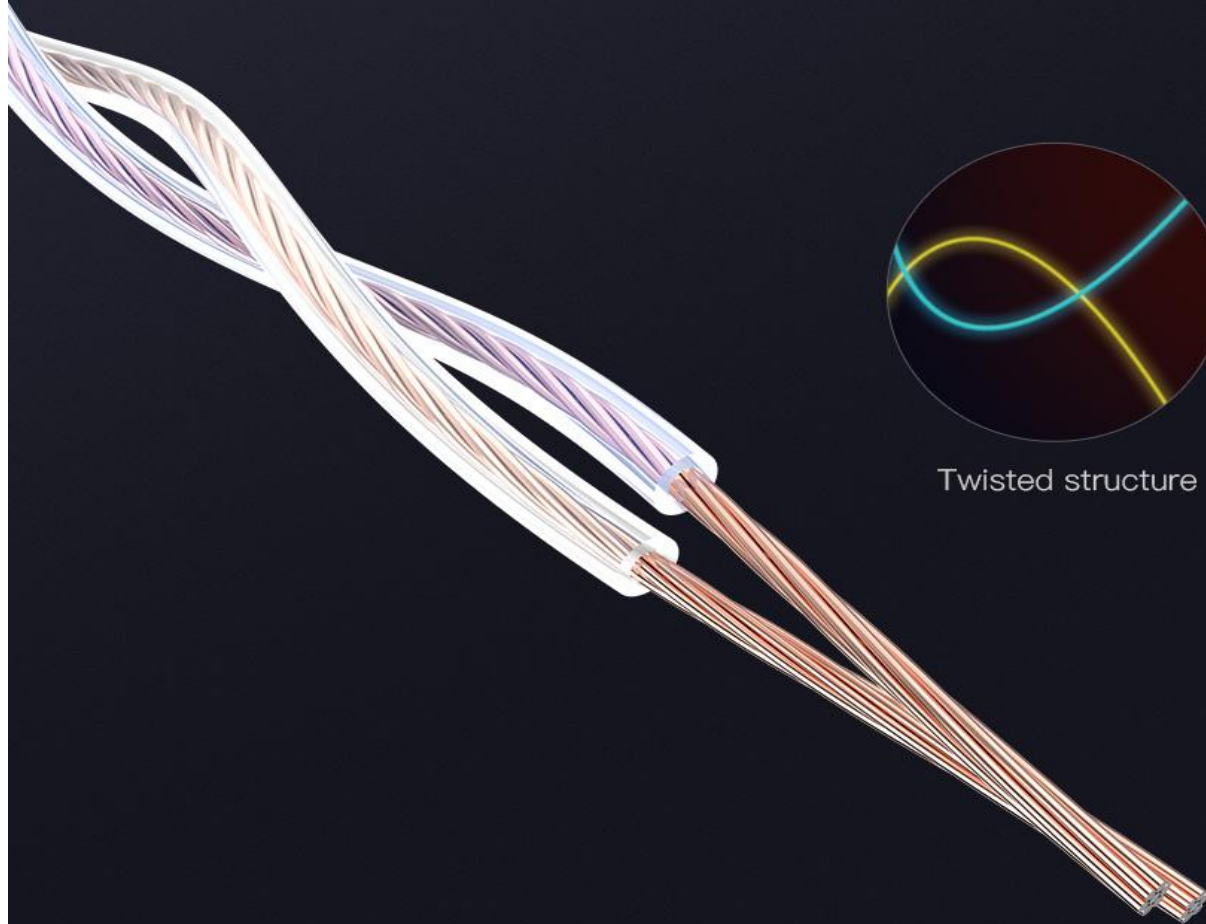

8P8C Gold-plated Contacts

Resistance to pluggable, stability signal and durable



Environmental PVC Jacket

Rugged, not broken



Cable OD 5.5mm

Strengthens the durability of wire



Scenes Display



Office wiring



Home decoration



Internet cafe cabling



Hotel apartment

Line Size

Meet different needs

The shortest length: 0.75m



The longest length: 50m

Black



Ice Blue



Product Parameters

Brand	Vention
Name	CAT5E UTP Patch Cable
Model	VAP-A10
Appearance Color	Ice Blue/Black
Wire Rod Structure	8P8C
Interface Type	RJ45
Conductor	CCA
Network Cable Type	UTP
Transmisson	100Mbps
Jacket	PVC
AWG	26AWG
OD	5.5mm
Mechanical Working Life	>10000 times
Length	0.75m-50m
Warranty	One Year
Packing	PE Bag(Below 20m)/Kraft Box (Above 20m)

* All data are from Vention laboratory




PE bag(Below 20m)



Kraft box(Above 20m)

Length	Art.No.	EAN Code
0.75m	VAP-A10-S075	6922794718920
1m	VAP-A10-S100	6922794718784
1.5m	VAP-A10-S150	6922794718791
2m	VAP-A10-S200	6922794718807
3m	VAP-A10-S300	6922794718814
5m	VAP-A10-S500	6922794718821
10m	VAP-A10-S1000	6922794718845
15m	VAP-A10-S1500	6922794718852
20m	VAP-A10-S2000	6922794718869

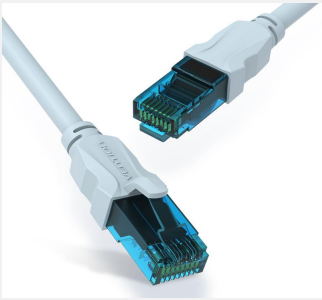

Package Contents

CAT 5E UTP Patch Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	200pcs(0.75m,1m),150pcs(1.5m,2m),100pcs(3m), 80pcs(5m), 40pcs(10m),25pcs(15m),28pcs(20m)
Carton Weight	5.9kgs(0.75m),6.6kgs(1m,1.5m),8kgs(2m), 7.4kgs(3m), 9.2kgs(5m), 8.5kgs(10m),7.6kgs(15m),14kgs(20m)
Package	Color box

www.ventioncable.com