


Technical data sheet

Screw-in beam clamp, with gland hole

Item no. 1488015

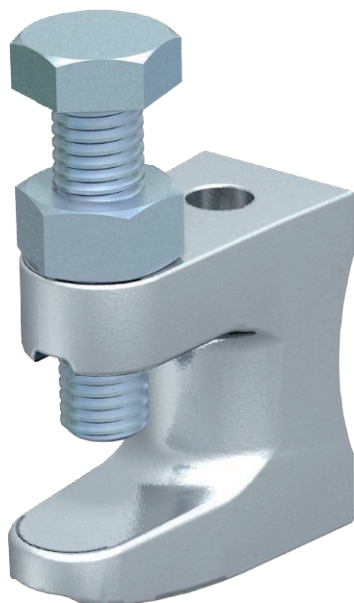

With gland hole.
Max. tightening torque: 8 Nm



TG Malleable iron

Master data

Item no.	1488015
Type	FL 1 TG
Description 1	Carrier screw clamp
Description 2	with fastening hole
Dimension	0-17mm
Material	Cast iron
Material symbol	TG
Smallest sales unit (VG)	50,00 Piece
Weight	8,50 kg/100 pc.


Technical data sheet

Screw-in beam clamp, with gland hole

Item no. 1488015



Technical data

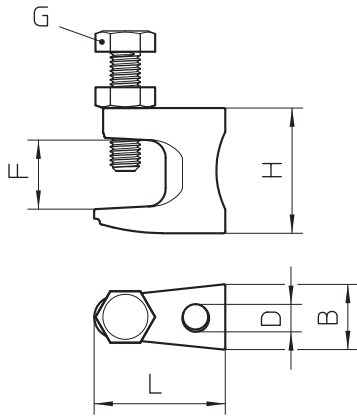

Length	38,00 mm
Width	19,00 mm
Height	35,00 mm
Dimension B	19,00 mm
Dimension D	9,00 mm
Dimension F	18,00 mm
Dimension G	M8
Dimension H	35,00 mm
Dimension L	38,00 mm
Connection type/component	Hole
Max. tightening torque	8,00 Nm
Fastening type	Screw
Fastening hole	9,00 mm
Breaking load	1,20 kN
Breaking load	1.200,00 N
Flangethickness	0,00 - 18,00 mm
Thread	M8
Thread size M	8,00
Hinge, adjustable	☐
Hinged	☐