


Technical data sheet

Straight connector 60

Item no. 6067603

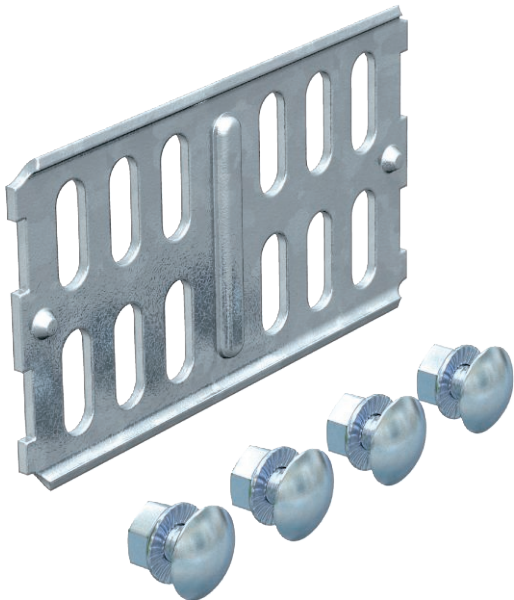

For straight connections of cable trays, fittings and barrier strips (FT) with a side height of 60 mm.



St	Steel
FT	Hot-dip galvanised

Additional product text, instruction	Including appropriate fastening material.
--------------------------------------	---

Master data

Item no.	6067603
Type	RLVK 60 FT
Description 1	Straight connector
Description 2	for cable tray
Dimension	60x100
Material	Steel
Material symbol	St
Surface	Hot-dip galvanised
Surface to DIN	DIN EN ISO 1461
Surface symbol	FT
Smallest sales unit (VG)	10,00 Piece
Weight	10,30 kg/100 pc.


Technical data sheet

Straight connector 60

Item no. 6067603



Technical data

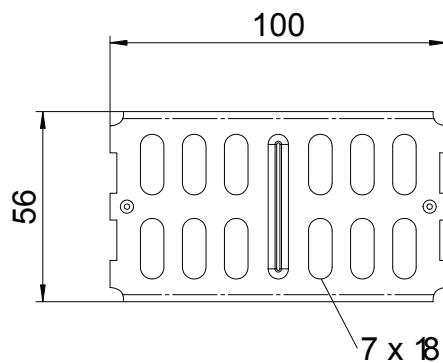

Length	100,00 mm
Height	60,00 mm
Side height	60,00 mm
Side height	2,00 in
Dimension	200 x 56 mm
Version	Straight connector
Plate thickness	2,00 mm
Suitable for cable tray	☒
Suitable for mesh cable tray	☐
Suitable for cable ladder	☐
Suitable for maintaining electrical function	☐
Adjustable connector, horizontal	☐
Adjustable connector, vertical	☐
Rustproof steel, pickled	☐
Connection type	Screw connector