


Technical data sheet

Straight and angle connector 60

Item no. 6067611

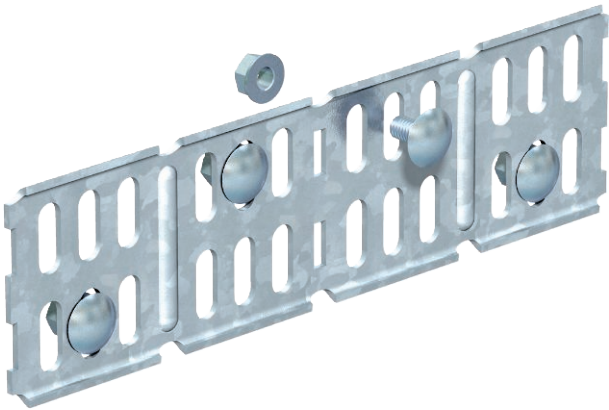

Straight and angle connector for cable trays and fittings with a side height of 60 mm.



- St

FT
- Steel

Hot-dip galvanised

Additional product text, instruction

Including appropriate fastening material.

Master data

Item no.	6067611
Type	RWVL 60 FT
Description 1	Straight and angle connector
Description 2	for cable tray, horizontal
Dimension	60x200
Material	Steel
Material symbol	St
Surface	Hot-dip galvanised
Surface to DIN	DIN EN ISO 1461
Surface symbol	FT
Smallest sales unit (VG)	10,00 Piece
Weight	17,40 kg/100 pc.


Technical data sheet

Straight and angle connector 60

Item no. 6067611



Technical data

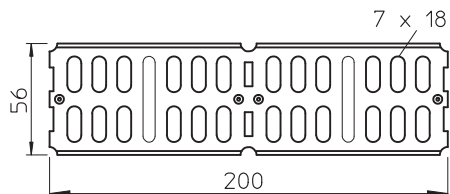

Length	200,00 mm
Height	60,00 mm
Side height	60,00 mm
Side height	2,00 in
Dimension	200 x 56 mm
Version	Angle connector
Plate thickness	2,00 mm
Suitable for cable tray system height	60,00 mm
Suitable for cable tray	☒
Suitable for mesh cable tray	☐
Suitable for cable ladder	☐
Suitable for maintaining electrical function	☐
Adjustable connector, horizontal	☐
Adjustable connector, vertical	☐
Rustproof steel, pickled	☐
Connection type	Screw connector