


Technical data sheet

Straight connector 60

Item no. 6208840

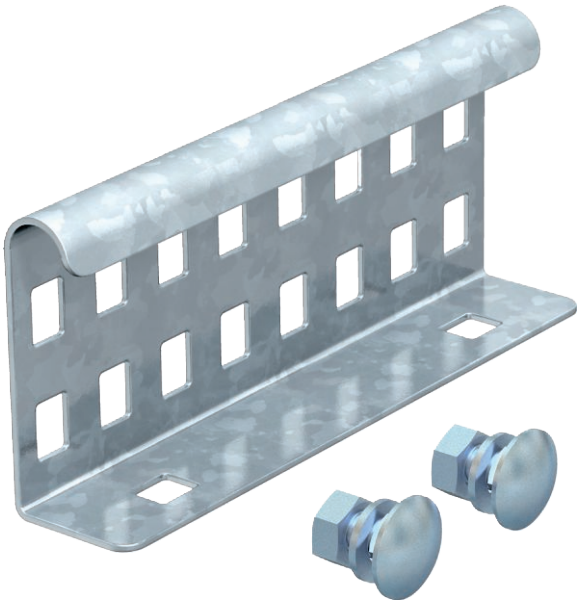

Straight connector as external connector to connect cable ladders and fittings with a side height of 60 mm and continuous rail perforation.

St	Steel
FS	Strip galvanised

Additional product text, instruction	The bolt fastening ensures the continuity of the equipotential bonding.
--------------------------------------	---

Master data

Item no.	6208840
Type	LVG 60 FS
Description 1	Straight connector
Description 2	for cable ladder
Dimension	64x150
Material	Steel
Material symbol	St
Surface	Strip galvanised
Surface to DIN	DIN EN 10346
Surface symbol	FS
Smallest sales unit (VG)	10,00 Piece
Weight	22,00 kg/100 pc.


Technical data sheet

Straight connector 60

Item no. 6208840



Technical data

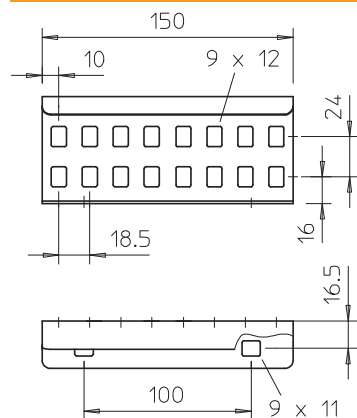

Height	64,00 mm
Side height	60,00 mm
Dimension	64x150 mm
Version	Straight connector
Plate thickness	1,50 mm
Suitable for cable tray	☐
Suitable for mesh cable tray	☐
Suitable for cable ladder	☒
Adjustable connector, horizontal	☐
Adjustable connector, vertical	☐
Rustproof steel, pickled	☐
Connection type	Screw connector