


Technical data sheet

Angle connector 60

Item no. 6208895

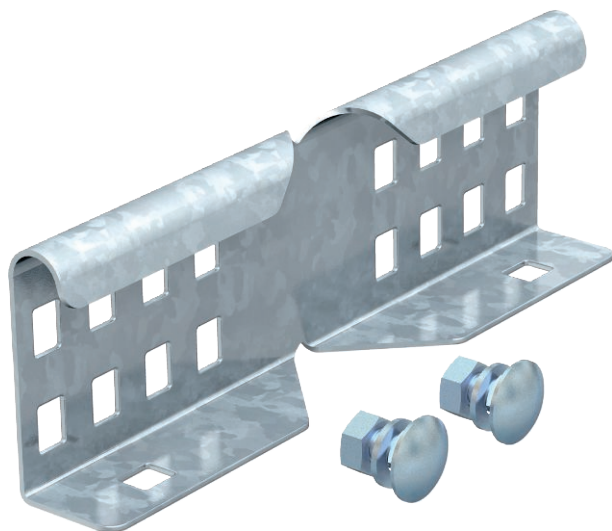

Angle connector as external connector to join cable ladders and fittings with a side height of 60 mm and continuous rail perforation.



St	Steel
FS	Strip galvanised

Additional product text, instruction

The bolt fastening ensures the continuity of the equipotential bonding.

Master data

Item no.	6208895
Type	LWVG 60 FS
Description 1	Angle connector
Description 2	for cable ladder
Dimension	64x200
Material	Steel
Material symbol	St
Surface	Strip galvanised
Surface to DIN	DIN EN 10346
Surface symbol	FS
Smallest sales unit (VG)	10,00 Piece
Weight	24,00 kg/100 pc.


Technical data sheet

Angle connector 60

Item no. 6208895



Technical data

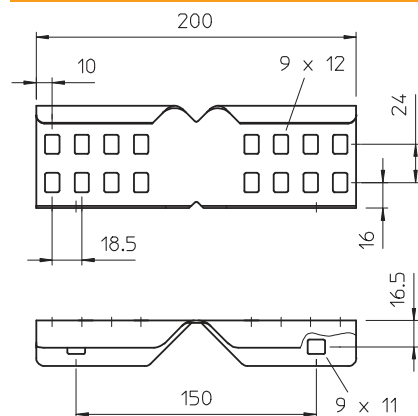

Height	64,00 mm
Side height	60,00 mm
Dimension	64x200 mm
Version	Angle connector
Plate thickness	1,50 mm
Suitable for cable tray	☐
Suitable for mesh cable tray	☐
Suitable for cable ladder	☒
Adjustable connector, horizontal	☐
Adjustable connector, vertical	☐
Rustproof steel, pickled	☐
Connection type	Screw connector