


Technical data sheet

Joint plate

Item no. 7070205

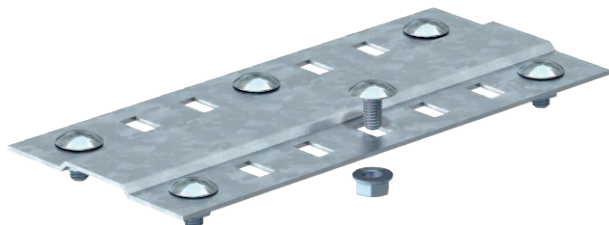

Wide joint plate for use in all cable trays and wide span cable trays.




St	Steel
FS	Strip galvanised

Additional product text, instruction	Including appropriate fastening material.
Product text, scope of delivery	For function maintenance at a width of 100 mm, the quantity of supplied M6 truss-head bolts should be increased to four, whilst for widths 200 and 300 mm, it should be increased to six.

Master data

Item no.	7070205
Type	SSLB 100 FS
Description 1	Joint plate
Description 2	wide, with 2 fastenings
Dimension	B100mm
Material	Steel
Material symbol	St
Surface	Strip galvanised
Surface to DIN	DIN EN 10346
Surface symbol	FS
Smallest sales unit (VG)	20,00 Piece
Weight	7,70 kg/100 pc.

Technical data

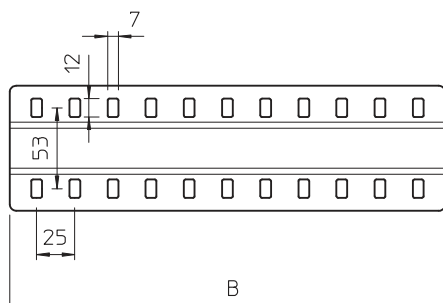

Length	100,00 mm
Width	85,00 mm
Width	4,00 in
Height	4,00 mm
Side height	35,00 mm
Dimension B	100,00 mm
Version	Joint plate
Quantity of bolts	2,00 pc.
Plate thickness	1,50 mm
Suitable for cable tray	☒
Suitable for mesh cable tray	☐
Suitable for cable ladder	☐
Suitable for maintaining electrical function	☒
Adjustable connector, horizontal	☐
Adjustable connector, vertical	☐
Rustproof steel, pickled	☐

Technical data sheet

Joint plate

Item no. 7070205



Technical data	
Connection type	Screw connector
Wide-span version	☒