


LB4H-IE/N

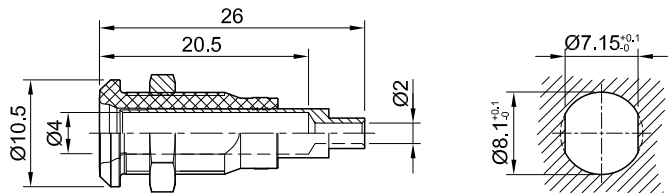

Item number 64.3042-*

Insulated, Ø 4 mm, rigid. Machined brass. The socket can be screw-mounted in predrilled panels. Solder connection.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 25 A / 60 V, 25 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	20212223242526272829
Thread	M8x0,5
Component parts	BI-LB4x-IE/N
Supplied assembly material	MU/M8x0,5