

Go Thru Screwdriver & Set

KT No. & D1



- Shank material - Chrome vanadium alloy steel
- Grip material - PP
- Finishing - chrome plated

1482



- Slotted head, hex-shank
- DIN ISO 2380

KT NO.	 mm	 inch	 mm	 mm	 inch	 mm		
14825503	5.5	7/32	0.8	75	3	5.0	54	12 / 240
14826504	6.5	1/4	1.2	100	4	6.0	93	12 / 144
14826504-E*	5.5	1/4	1.2	100	4	6.0	112	12 / 96
14826505-E*	6.5	1/4	1.2	125	5	6.0	116	12 / 144
14826506	6.5	1/4	1.2	150	6	6.0	103	12 / 144
14820806	8.0	5/16	1.2	150	6	8.0	174	12 / 144
14821012	10.0	12/32	1.6	300	12	10.0	326	10 / 40

* Enlarged handle



36206MR

Contents



0.97



1 / 20




1481

PH1 x 75, PH2 x 100, PH3 x 150



1482

5.5 x 75, 6.5 x 150,
8.0 x 150

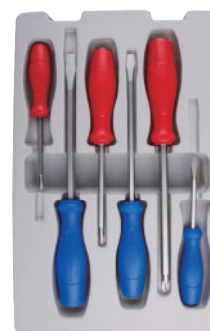


6
PC.

35114MR

- Standard & insulated & go thru screwdriver set

35114MR01

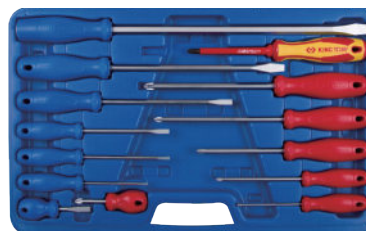

14
PC.

KT NO.			Contents		
35114MR	1472	6.5 x 150	PH0 x 75, PH1 x 100, PH2 x 100, PH2 x 150, PH2 x 38, PH3 x 150	2.40	1 / 4
35114MR01	1478	PZ2 x 100	3 x 75, 4 x 100, 5.5 x 100, 6.5 x 150, 6.5 x 38, 8 x 200		
			10 x 300		

