

 
 
 
Straight Ring Wrench & Set

KT No. & D1

19C0

- Thin wall rings
- Chrome vanadium alloy steel
- Chrome plated
- DIN 837

KT NO.	Size mm	L mm		
19C00607	6 x 7	121	20	20 / 480
19C00809	8 x 9	137	33	20 / 480
19C01011	10 x 11	154	52	20 / 320
19C01213	12 x 13	164	69	20 / 240
19C01415	14 x 15	182	85	20 / 240
19C01617	16 x 17	211	127	12 / 144
19C01819	18 x 19	226	160	12 / 144
19C02022	20 x 22	240	208	10 / 120
19C02123	21 x 23	255	238	10 / 120
19C02426	24 x 26	270	316	6 / 72
19C02528	25 x 28	285	368	6 / 72
19C03032	30 x 32	335	540	5 / 40




► Nylon pouch bag

KT NO.	PC.	Contents		
1C08MR	8	6 x 7, 8 x 9, 10 x 11, 12 x 13, 14 x 15, 16 x 17, 18 x 19, 20 x 22	0.79	1 / 24
1C12MR	12	6 x 7, 8 x 9, 10 x 11, 12 x 13, 14 x 15, 16 x 17, 18 x 19, 20 x 22, 21 x 23, 24 x 26, 25 x 28, 30 x 32	2.23	1 / 12

0° Offset Ring Wrench

19B0

- Ideal for crowded or confined spaces
- Ultra-compact ring head
- Chrome molybdenum alloy steel
- Chrome plated
- DIN 3113

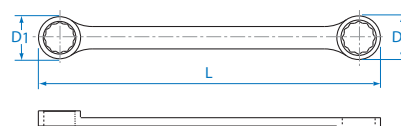

KT NO.	Size mm	D1 mm	D2 mm	L mm		
19B00810	8 x 10	12.5	15	235	72	12 / 240
19B01011	10 x 11	14.3	17	291	95	12 / 192
19B01012	10 x 12	14.3	17	291	95	12 / 192
19B01113	11 x 13	17.8	20.3	328	157	12 / 120
19B01214	12 x 14	17.8	20.3	328	157	12 / 120
19B01315	13 x 15	20.2	23.3	368	217	12 / 96
19B01417	14 x 17	20.2	23.3	368	217	12 / 96
19B01618	16 x 18	23.7	26.6	407	284	12 / 72
19B01719	17 x 19	23.7	26.6	407	284	12 / 72
19B01921	19 x 21	27.5	29.7	415	376	8 / 64
19B02224	22 x 24	31.3	34.0	430	482	6 / 48