


Insert Adapter



34505102R

KT NO.	 mm	 mm	L1 mm	L mm		
34505102R	9 x 12	14 x 18	20.5	45.5	82.2	12 / 144

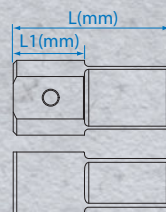

34505201R


KT NO.	 mm	 mm	L1 mm	L mm		
34505201R	14 x 18	9 x 12	33.5	49.5	131.8	12 / 144

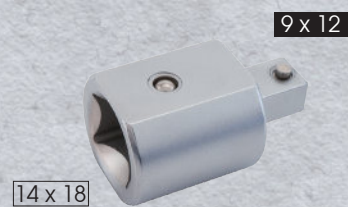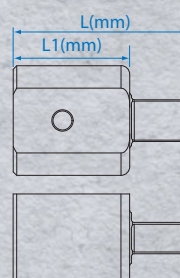

Hook Wrench Head & Set

345042M

KT NO.	Size mm	Capacity mm	Maximum Torque N·m	Lw* mm	L mm		
34504236M	36	28-36	354	77	121	248.20	12 / 72
34504245M	45	40-45	377	77	129	274.00	12 / 72
34504255M	55	50-55	398	77	129	263.20	12 / 72
34504262M	62	58-62	421	77	134	278.20	12 / 72
34504275M	75	68-75	444	77	139	294.60	12 / 72
34504290M	90	80-90	465	77	142	288.80	12 / 72

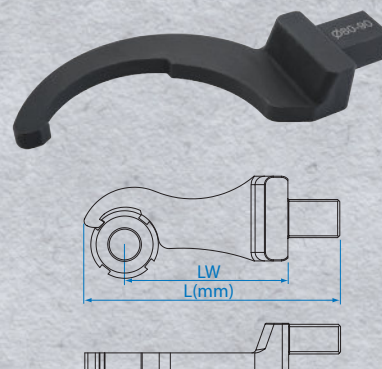

3452407MR

- Suitable for tightening round nuts with radial notches
- Applied with interchangeable torque wrench
- Widely used in automobile, machine tool building and petroleum industries

Contents

 2.48  1 / 6

 34505102R 9 x 12(F) → 14 x 18(M)

 345042M 36, 45, 55, 62, 75, 90



7
PC.

