

Continuous Flow Air Grease Gun with 12" Tube

9BV14T

- Ideal for machine, automobile, farm and garden equipments, vehicles etc.
- 360° rotating handle





KT NO.	Air Inlet (Inch)	Screw Thread	Air Source Range input (psi/bar)	output (psi/bar)	Recommended Air Source input (psi/bar)	output (psi/bar)	Capacity c.c.	oz	Kg	Box
9BV1420T	1/4"BSPT	M10 x 1.0P	60~150 psi (4.2~10.3 bar)	2400~6000 psi (165~413 bar)	90 psi (6.2 bar)	3600 psi (250 bar)	400	14	1.7	1 / 10
9BV1411T	1/4"NPT	1/8"-28NPT	60~150 psi (4.2~10.3 bar)	2400~6000 psi (165~413 bar)	90 psi (6.2 bar)	3600 psi (250 bar)	400	14	1.7	1 / 10
9BU8109	9" length	1/8"-28NPT								
9BU8209	9" length	M10 x 1.0P								
9BU8112	12" length	1/8"-28NPT								
9BU8212	12" length	M10 x 1.0P								

9BV1411T For general market except North America, Germany, South Africa, Egypt
 9BV1420T For Germany, South Africa, Egypt, etc.

Air Blow Gun

7990

- Ideal for cleaning
- Steel nozzle & nylon fiber handle
- Air pressure : 90 psi recommended
- Air consumption : 1/4" hose-13cfm-350l/min, 3/8" hose-15cfm-430l/min
- Sound pressure : 85~90 dB
- Working pressure : 75~120 psi/5.3~8.4 kgf/cm²
- Max pressure : 200 psi/ 14.07 kgf/cm²

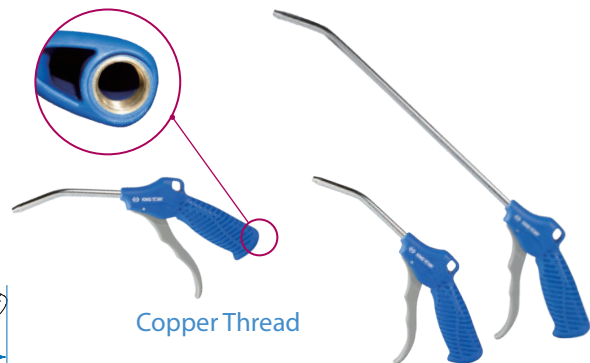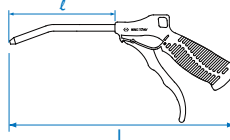

KT NO.	Air Inlet Inch	ℓ Inch mm	L (mm)	g	Box
79900-04	1/4"BSPT	4 100	245	200	20 / 100
79900-10	1/4"BSPT	10 250	420	240	25 / 50
79900-13	1/4"BSPT	13 330	475	260	25 / 50
79900-20	1/4"BSPT	20 500	650	300	25 / 50

KT NO.	Air Inlet Inch	ℓ Inch mm	L (mm)	g	Box
79901-04	1/4"NPT	4 100	245	200	20 / 100
79901-10	1/4"NPT	10 250	420	240	25 / 50
79901-13	1/4"NPT	13 330	475	260	25 / 50
79901-20	1/4"NPT	20 500	650	300	25 / 50

Spray Gun

79982

- Suitable for spraying a wide range of oils, cleaning agents and rustproofing liquids
- Fitted with fluid/air control valve



79982-06



79982-10

KT NO.	Max Capacity	Working Pressure(psi)	Air inlet connection	g	Box
79982-06	600 c.c	90-150	1/4"	600	1 / 10
79982-10	1000 c.c	90-150	1/4"	800	1 / 10