


Speed Regulating Type Hydraulic Garage Jack

9TY137B


- hydraulic speed regulating

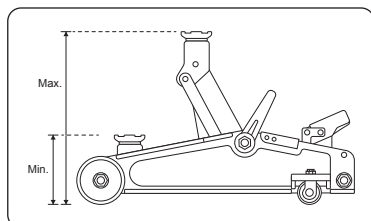

KT NO.	Capacity (T)	Min height (mm)	Max height (mm)	N.W (kg)	G.W (kg)	CUFT
9TY137B-02A-B	2	135	330	8.5	9	0.49

9TY133A


- hydraulic speed regulating
- Extra low profile design
- Extra carry handle for convenient transportation

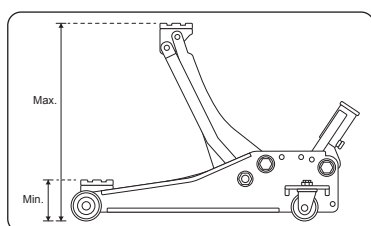

KT NO.	Capacity (T)	Min height (mm)	Max height (mm)	N.W (kg)	G.W (kg)	CUFT
9TY133A-25A-B	2.5	75	515	33.8	35.7	1.96

9TY132D

- hydraulic speed regulating
- Foot pedal design for quick lift

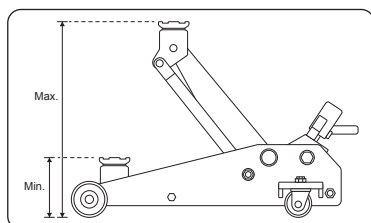

KT NO.	Capacity (T)	Min height (mm)	Max height (mm)	N.W (kg)	G.W (kg)	CUFT
9TY132D-03A-B	3	145	500	37.2	38.6	1.99