

Blank bottom plate with seal, WxD=332x172mm

Part no. SFP-172X332-CS
 Catalog No. 138742

EL-Nummer 2466294
 (Norway)

Delivery program

Product range			Accessories CS
Accessories			Bottom plates
Description			Without apertures With continuous foamed gasket
For use with enclosure			
Width		mm	400
Material			Steel plate
Surface finish			Semi-textured

Technical data

General

Degree of Protection			IP66
----------------------	--	--	------


Material characteristics

Material			Steel plate
Surface treatment			Structured powder spray polyester based paint finish
Surface finish			Semi-textured
Colour			light gray (RAL 7035)
Finish			Gloss
Material thickness		mm	
Bottom plate		mm	2

Technical data ETIM 8.0

Distribution boards (EG000023) / Gland plate for enclosure/cabinet (EC000211)			
Electric engineering, automation, process control engineering / Electrical installation, device / Electrical distribution system (incl. small distribution board) / Gland plate for small distribution boards/switchgear cabinets (ecl@ss10.0.1-27-14-24-21 [ADI315007])			
Model			Blind
Type			Straight
Width		mm	332
Height		mm	5
Depth		mm	172
Material			Steel
Surface protection			Powder coating
Degree of protection (NEMA)			Other
Pre-stamping			No
Number of connector holes			0
Thread type			None
Suitable for nominal thread metric/PG			0 - 0

Dimensions

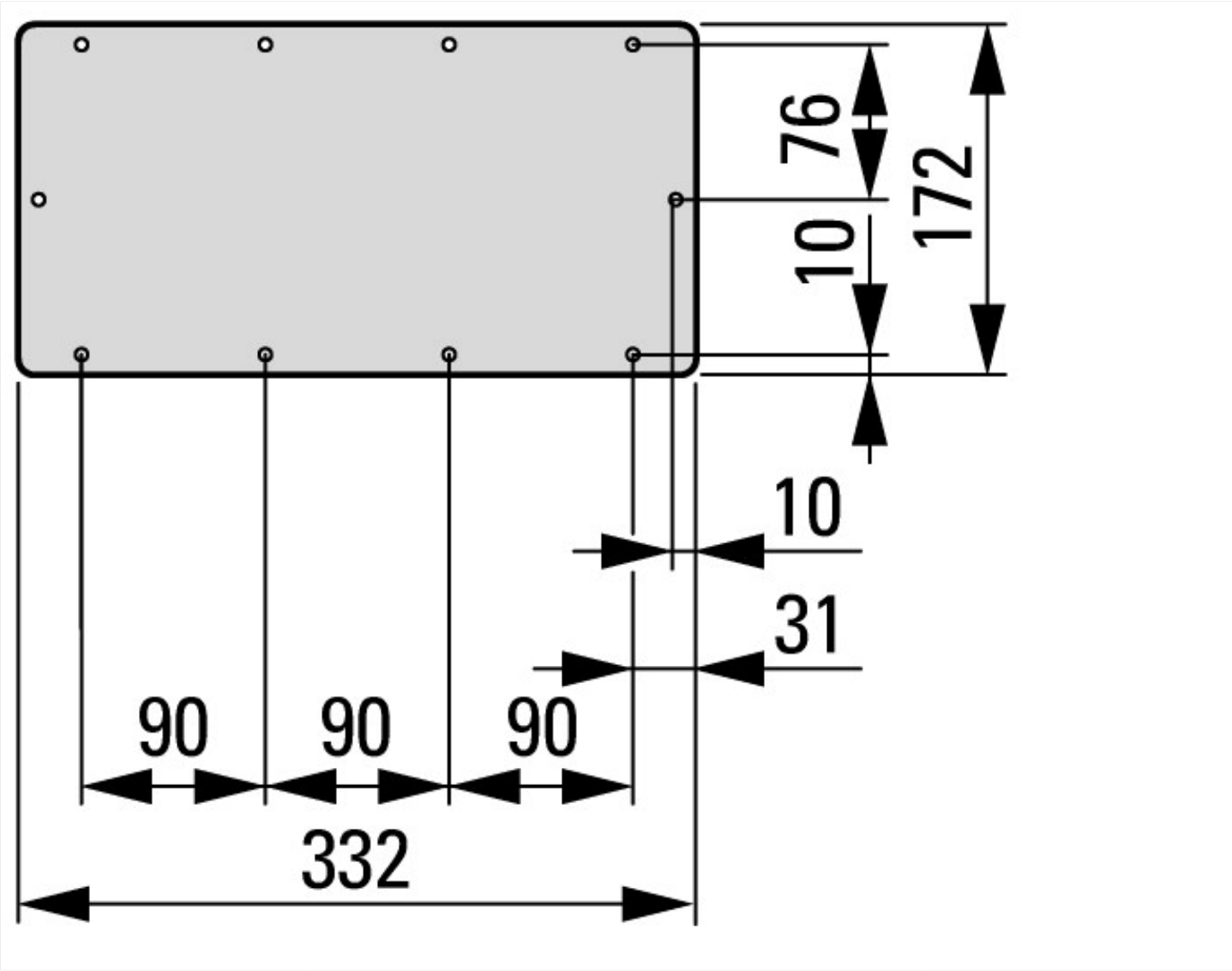

Additional product information (links)

AWA4300-2521 CS sheet steel wall-mounting enclosure

AWA4300-2521 CS sheet steel wall-mounting enclosure

https://es-assets.eaton.com/DOCUMENTATION/AWA_INSTRUCTIONS/25210414.pdf